


UTC-P01

Camera Module for UTC-500 Series

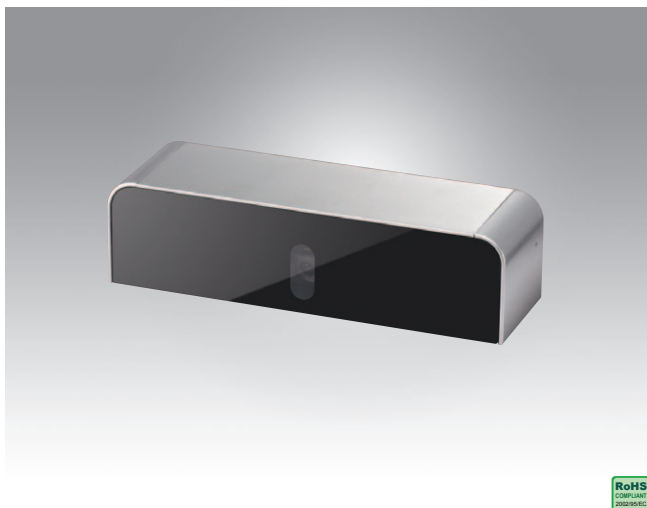

Specifications

Interface	USB (Cable Length:50cm)
Image Resolution	2592 (H) x 1944 (V)
Focusing Range	10 cm~ ∞; Supports auto focus
Frame Rate	640 x 480 @ 30 fps max 1280 x 1024 @ 30 fps max 1600 x 1200 @ 15 fps max 2592 x 1944 @ 15 fps max
Video Format	MJPEG
OS Support	Windows XP/7/8
Dimensions	130 x 35 x 40 mm
Operating Temperature	0 ~ 40° C

Packing List


Description	Quantity
Cable Clamp	2
Camera Module Unit	1

Ordering Information

P/N	Description
UTC-P01-A1E	5MP camera module for UTC-500 series

UTC-P02

Magnetic Stripe Card Reader for UTC-500 Series

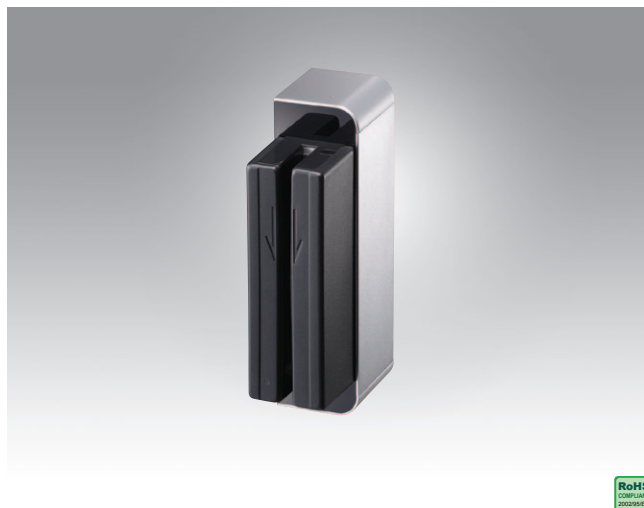

Specifications

Interface	USB (Cable Length:50cm)
Track Configuration	TRACK 1 / IATA / 210 bpi / 79 Alphanumeric Characters TRACK 2 / ABA / 75 bpi / 40 Numeric Characters TRACK 3 / Thrift / 210 bpi / 107 Numeric Characters
Card Standard	ANSI, ISO, and ABA.
Read Speed	3 ips to 60 ips (7 cm/s to 152 cm/s)
Magnetic Head Life	1,000,000 times (ISO test standard)
OS Support	Windows 98/ME/2000/XP / Win 7
Dimensions	130 x 35 x 40 mm
Operating Temperature	0 ~ 40° C

Packing List

Description	Quantity
Cable Clamp	2
Magnetic Stripe Reader Unit	1

Ordering Information

P/N	Description
UTC-P02-A0E	Magnetic stripe reader For UTC-500 series

UTC-500 Peripherals Series Installation Guide



The UTC-500's uniquely designed Side groove creates an attachment area that runs all around the frame; customer can easily attach Peripherals to it where they need



Attach the UTC-peripheral to the UTC 500 series side groove



Fasten the 2 screws to fix the peripheral in place

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[UTC-P02-A0E](#)