

WIN-DH0-135BS4U

Active 4U 135W CPU Cooler for Intel® Socket H



Features

- High performance and low noise fan design
- IPC system application
- Oxygen-free copper and aluminum heat sink
- Industrial level side blow two ball bearing fan
- Ultra slim heat pipe
- Supports PWM
- 5-year warranty




Specifications

Compatible Socket		LGA 1150/1156/1155
Heat Sink	Heat Pipe	Yes
	Material	CU + Al
Fan	Dimensions (W x H x D)	90 x 90 x 25 mm / 3.54" x 3.54" x 0.98"
	Speed	5,000 RPM
	Air Flow	108.08 CFM
	Air Pressure	13.57 mm H2O
	Rated Voltage	12 V
	Rated Current	1 A
	Power Consumption	12 W
	Bearing Type	2 Ball
	Noise Level	59 dBA max.
	Connector	4-pin
	MTBF (hr)	70,000 @ 40°C
Max. Cooling Capacity		135 W
Cooler Height		4U
Dimensions (W x H x D)		88.2 x 88.2 x 112.15 mm / 3.47" x 3.47" x 4.42"
Weight		583 g / 1.29 lb.
Warranty		5 years

Dimensions

Unit: mm

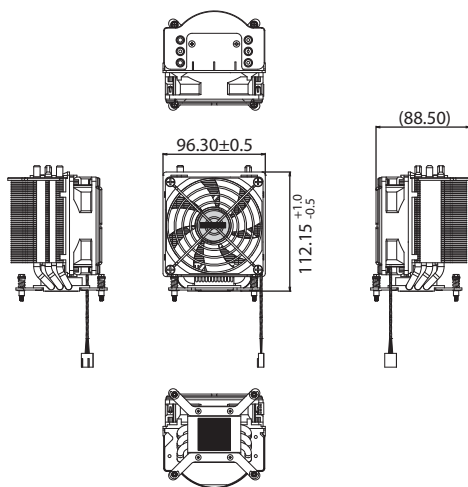

Ordering Information

Part Number	Description
WIN-DH0-135BS4U	Cooler Socket H 135W 88.2 x 88.2 x 112.15 mm Act.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[WIN-DH0-135BS4U](#)