


SQR-SD4N(E)

ECC SODIMM DDR4

SQR-RD4N

Registered DIMM DDR4

NEW

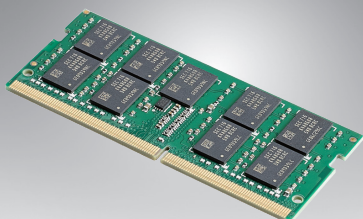

CE FCC

Features

- JEDEC Standard 260-pin Small Outline Dual In-Line Memory Module
- Data Transfer Rate: 2666 MT/s
- ECC function support
- Anti sulfuration DRAM module
- Original Samsung IC chip


Specifications

DDR Type	DDR4
Pin / DIMM	260pin ECC SODIMM
Data Transfer Rate	2666 MT/s
Golden Finger	30u"
Capacity	4GB ~ 32GB
Power Supply	1.2V (1.26V~1.14V)
Operating Temperature	0 ~ 85 °C
Dimensions (mm)	69.6 x 30 ± 0.13

Ordering Information

PN	Description
SQR-SD4N4G2K6SEEB	260pin ECC SODIMM DDR4 2666 4GB 512Mx8 (0 ~ 85 °C) SAM
SQR-SD4N8G2K6SEBCB	260pin ECC SODIMM DDR4 2666 8GB 1Gx8 (0 ~ 85 °C) SAM
SQR-SD4N16G2K6SECB	260pin ECC SODIMM DDR4 2666 16GB 1Gx8 (0 ~ 85 °C) SAM
SQR-SD4N32G2K6SEME	260pin ECC SODIMM DDR4 2666 32GB 1.2v 2Gx8 (0 ~ 85 °C) SAM

NEW

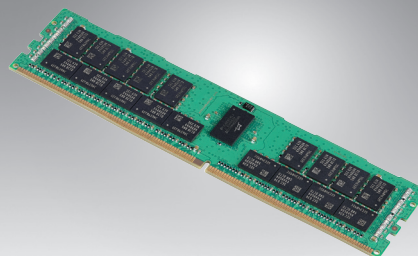

CE FCC

Features

- JEDEC Standard 288-pin Registered Dual In-Line Memory Module
- Data Transfer Rate: 2666 MT/s
- ECC Registered
- Anti sulfuration DRAM module
- Original Samsung IC chip

Specifications

DDR Type	DDR4
Pin / DIMM	288pin Registered DIMM
Data Transfer Rate	2666 MT/s
Golden Finger	30u"
Capacity	8GB ~ 32GB
Power Supply	1.2V (1.26V~1.14V)
Operating Temperature	0 ~ 85 °C
Dimensions (mm)	133.35 x 31.25

Ordering Information

PN	Description
SQR-RD4N8G2K6SZBCB	288pin RDIMM D4 2666 8GB 1Gx8, (0 ~ 85 °C), SAM
SQR-RD4N16G2K6SZCB	288pin RDIMM D4 2666 16GB 1Gx8, (0 ~ 85 °C), SAM
SQR-RD4N32G2K6SRCB	288pin RDIMM D4 2666 32GB, 2Gx4, (0 ~ 85 °C), SAM

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[SQR-SD4N4G2K6SEEEB](#) [SQR-SD4N16G2K6SECB](#) [SQR-SD4N32G2K6SEME](#) [SQR-SD4N8G2K6SEBCB](#)