

5

4

3

2

1

D

D

C


C

B

B



A

A

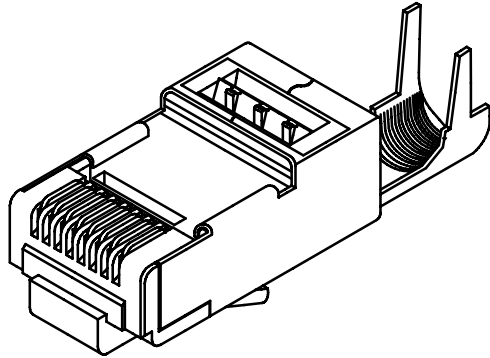

Description: Eight Conductor MOD Plug, Shield
Part No: 32-2298UL
Plug Tolerance and DIM: Complies with F.C.C requirements
Flame and Extinguish: 94-V0
Operation Temperature: -40°C to +85°C
Contact Resistance: 10 Milliohms Max.
Current/Voltage: 30 VAC/42 VDC at 1.5 AMPS
Material: Shield .012THK CDA-260 1/4 HARD BRASS
100-150 MICRO-INCH TIN PLATED
Housing Polycarbonate
Contact Phosphor bronze-.012THK
Gold plated

RoHS Compliance: Yes
Technical Detail: Meets or exceeds Category 5e TIA/EIA 568-B.2

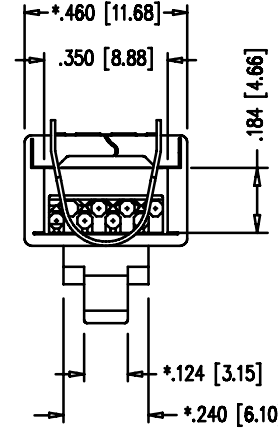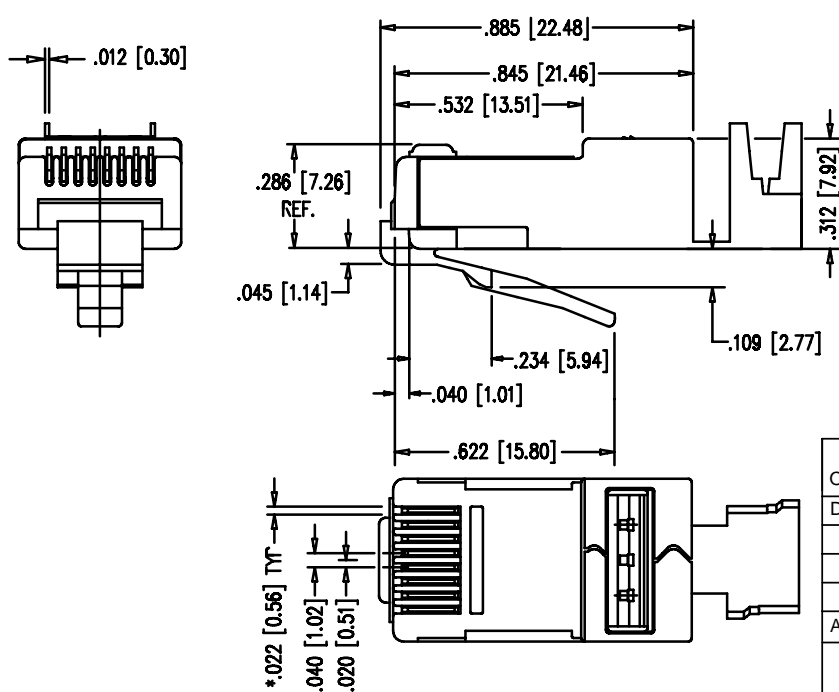

TOLERANCE UNLESS OTHERWISE SPECIFIED		DRAWN BY	DATE
DECIMALS	mm	TERRY.W	03-13-09
X	± 0.5	CHECKED BY	DATE
X.X	± 0.2	BETTY.YU	03-13-09
X.XX	± 0.1	APPROVED BY	DATE
ANGLES	± 0.5°	THOMAS	03-16-09
		U/M	mm

THIS DRAWING WAS PRODUCED BY COMPUTER,
DO NOT SCALE DRAWING OR UPDATE MANUALLY.

DRAWING NO.

32-2298UL-CUST

REVISIONS

01

OFFICIAL RELEASE

10-13-09

T

W

B

Y

T

02

TYPO MISTAKE: BRESS SHOULD
BE BRASS
UPDATE SPECIFICATIONS

08-14-12

Y

G

Y

G

M

L

ECO-12-0208

CUSTOMER COPY

Connectivity
Solutions

TITLE

Eight Conductor MOD Plug, Shield

SHEET
1 OF 1DRAWING NO.
32-2298UL-CUSTSIZE
A

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Cinch Connectivity Solutions:](#)

[32-2298UL](#)