

Description: Stright BNC Crimp Plug For RG58 Style Cable

Part No: CPMC881

Application: For Cable RG58 Style

Crimp Tool: 24-9958P

Impedance: 50 Ohms

Fequency Range: 0-4 GHz




Material:

Body	Zinc	Nickel Plated
Contact	Brass	Gold Plated
Insulator	POM	
Crimp Sleeve	Brass	Nickel Plated
Coupling Nut	Zinc	Nickel Plated

RoHS Compliance: Yes

Technical Detail: Refer to Emerson Document P/N 27-0000

DRAWING NO.									
CPMC881-CUST									
REVISIONS									
01	OFFICAL RELEASE								
	03-05-09	Z	B	T					
02	RELEASE FOR SUPPLIER ALTER								
	07-27-11	Y	Y	M					
03	INSULATOR MATERIAL WAS PTFE BODY MATERIAL WAS BRASS DIMENSIONS 11.5±0.1 WAS 12.1±0.1; Ø5.6 WAS Ø5.23; Ø6.5 WAS Ø6.22;15.0±0.3 WAS 14.8 ADDED: CABLE STRIP DIMENSIONS								
	07-27-11	Y	Y	M					ECO-11-0270

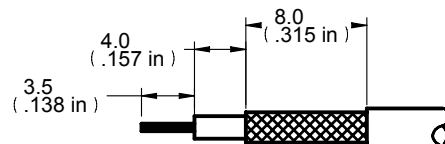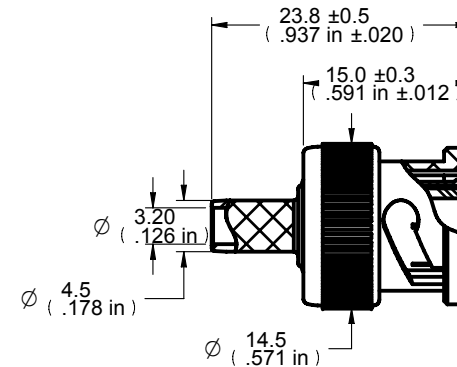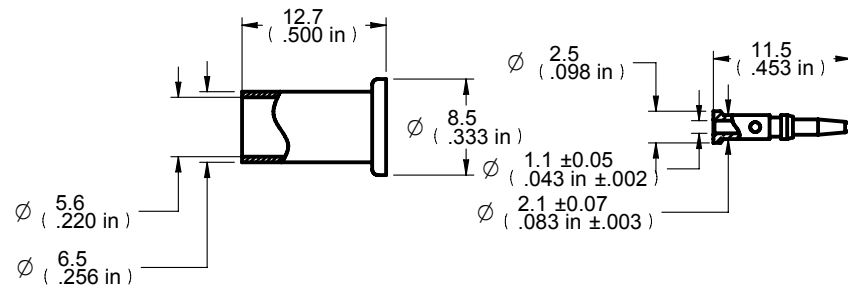

CABLE STRIP DIMENSIONS

DIM OUTLINE

TOLERANCE UNLESS OTHERWISE SPECIFIED		DRAWN BY	DATE
DECIMALS		YUGE HU	07-27-11
X	± 0.5	CHECKED BY	DATE
X.X	± 0.2	YUGE HU	07-27-11
X.XX	± 0.1	APPROVED BY	DATE
ANGLES	± 0.5°	LIN MA	07-27-11
		U/M	mm

THIS DRAWING WAS PRODUCED BY COMPUTER,
DO NOT SCALE DRAWING OR UPDATE MANUALLY.

Connectivity Solutions		
TITLE		
STRAIGHT BNC CRIMP PLUG FOR R58 STYLE CABLE		
SHEET	DRAWING NO.	SIZE
1 OF 1	CPMC881-CUST	A

CUSTOMER COPY

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Cinch Connectivity Solutions:](#)

[CPMC-88-1](#)