


RoHS COMPLIANT

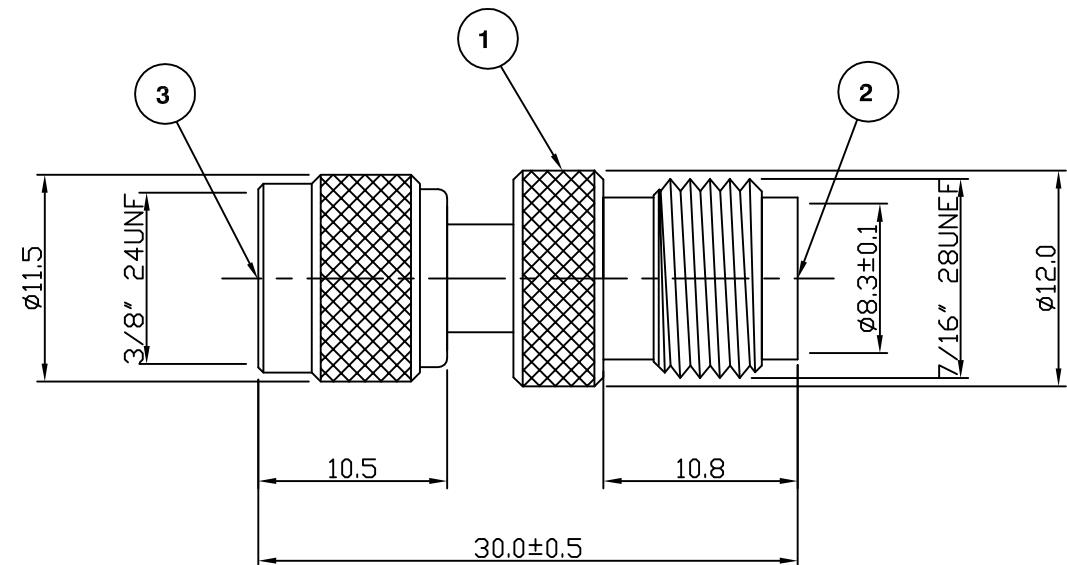

Electrical Characteristics

Nominal Impedance: 50 ohms
Frequency Range: DC to 2.5 GHz
Operating Voltage (rms): 335 V maximum at sea level

Mechanical Characteristics

Mating Cycles: 500 cycles minimum

Environmental Characteristics

Temperature Range: -55 °C to +85 °C

PART	DESCRIPTION
1	Body Brass, nickel plated
2	Dielectric POM
3	Contact Brass, gold plated

CAD Issue	SN	2	03 Oct 02
First Issue	IS	1	13 Nov 93
DESCRIPTION OF REVISION			APPVD ISS DATE



Cinch Connectivity Solutions
7-13 Russell Way,
Widford Industrial Estate,
Chelmsford, Essex,
CM1 3AA, UK.
Tel: +44 (0) 1245 359515
Fax: +44 (0) 1245 358938

SCALE: Not To Scale
DRAWN BY: S Nash
DIMENSIONS: mm
CHECKED BY: P Couzens
TOLERANCES: ± 0.2mm unless otherwise stated
APPROVED BY: P Couzens
DATE: 03 Oct 02

TITLE:
Mini UHF Plug to TNC
Jack

PART NUMBER:
VA302

PAGE: 1 of 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Cinch Connectivity Solutions:](#)

[VA302](#)