
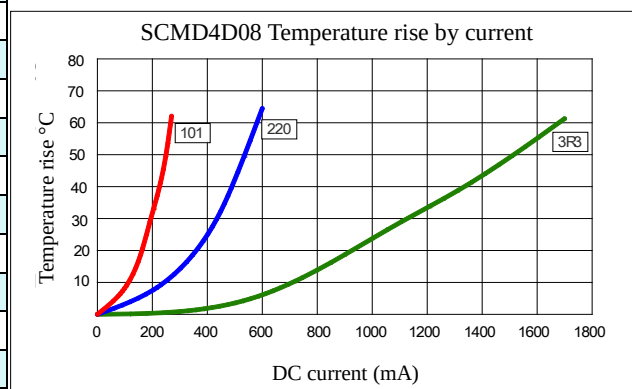


SMD POWER INDUCTORS

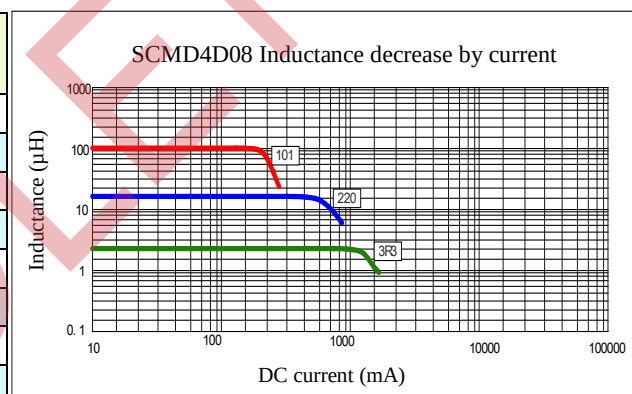

1. Open frame construction
2. Excellent Power Density
3. Engineered to Provide High Efficiency

ELECTRICAL CHARACTERISTICS

[illegible]

- (1). Inductance tolerance $\pm 20\%$ tested at 0.25V, 0ADC and 25°C.
- (2). DCR measured at 25°C.
- (3). The DC current at which the inductance decreases by 10% from its initial value.
- (4). The DC current that results in a 40°C temperature rise from 25°C ambient.

[Click here for QUANTITY PER REEL & PACKING INFORMATION](#)

Custom versions available upon request.

© 2019 Signal Transformer –Specification subject to change without notice. 12.19

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Bel:

[SCMD4D08-330](#) [SCMD4D08-270](#) [SCMD4D08-100](#) [SCMD4D08-6R8](#) [SCMD4D08-150](#) [SCMD4D08-101](#)
[SCMD4D08-3R3](#) [SCMD4D08-220](#) [SCMD4D08-4R7](#) [SCMD4D08-470](#)