
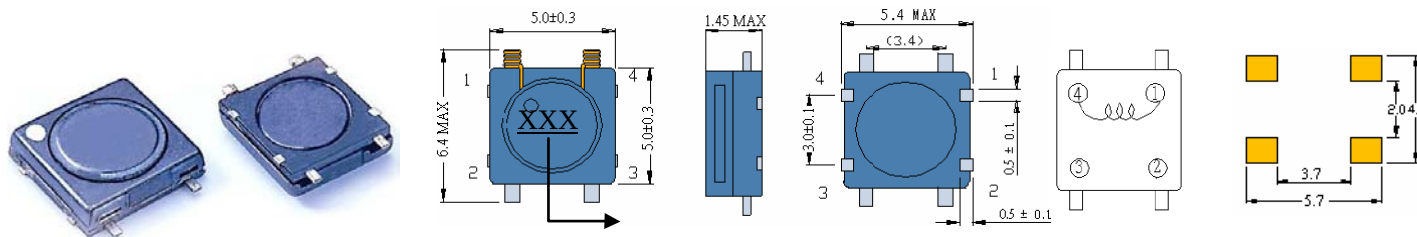
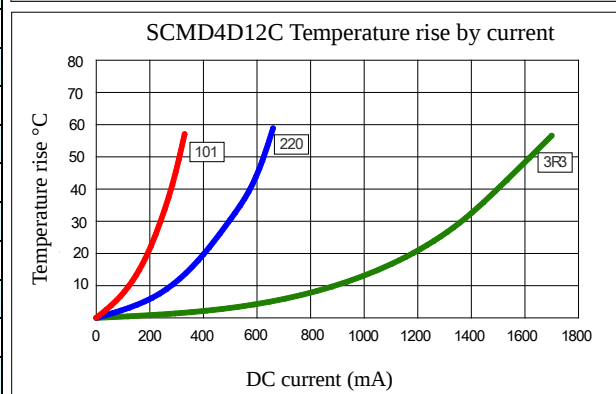


SMD POWER INDUCTORS

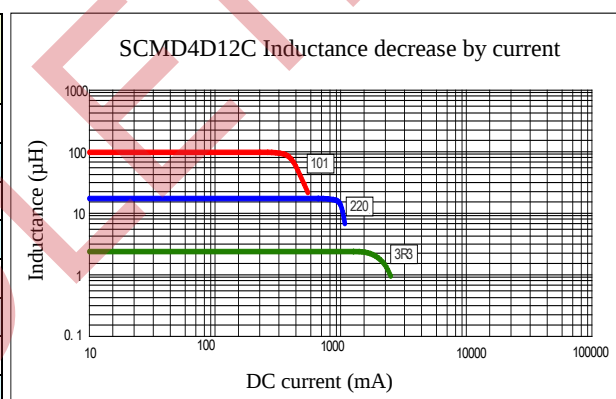

1. Magnetically shielded construction – Low EMI
2. Excellent Power Density
3. Engineered to Provide High Efficiency

ELECTRICAL CHARACTERISTICS

[illegible]

- (1). Inductance tolerance $\pm 20\%$ tested at 0.25V, 0ADC and 25°C.
- (2). DCR measured at 25°C.
- (3). The DC current at which the inductance decreases by 10% from its initial value.
- (4). The DC current that results in a 40°C temperature rise from 25°C ambient.

[Click here for QUANTITY PER REEL & PACKING INFORMATION](#)

Custom versions available upon request.

© 2019 Signal Transformer –Specification subject to change without notice. 12.19

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Bel:](#)

[SCMD4D12C-6R8](#) [SCMD4D12C-4R7](#) [SCMD4D12C-3R3](#) [SCMD4D12C-680](#) [SCMD4D12C-470](#) [SCMD4D12C-100](#)
[SCMD4D12C-101](#) [SCMD4D12C-330](#) [SCMD4D12C-220](#) [SCMD4D12C-150](#)