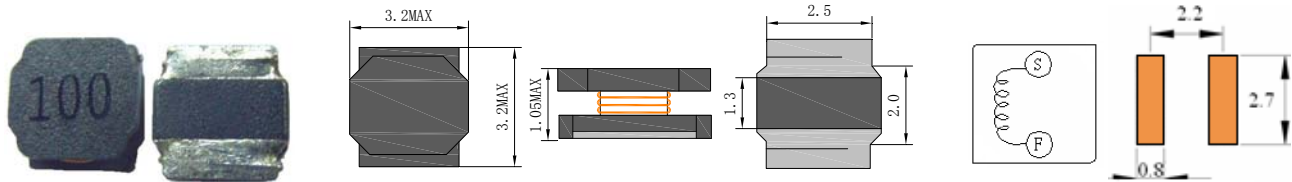


SMD POWER INDUCTORS

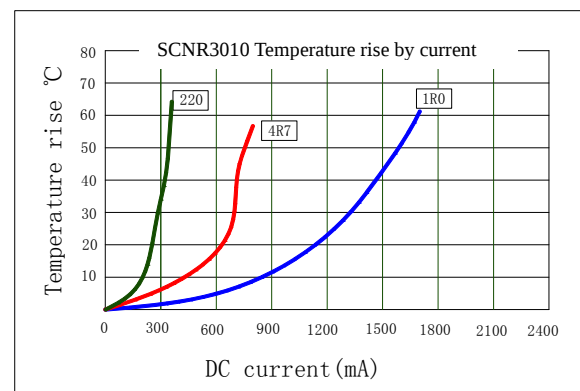
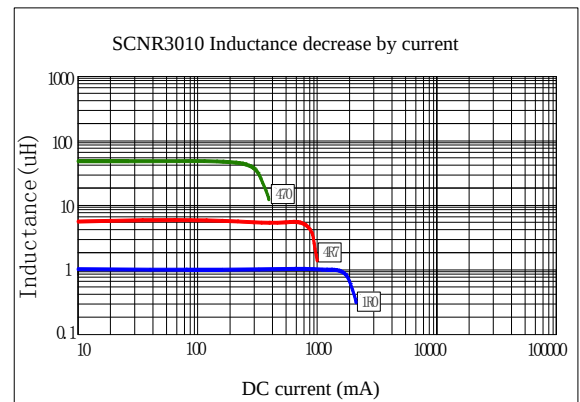


- Features

- ### 1. Open frame construction.



ELECTRICAL CHARACTERISTICS

[illegible]

(1). Inductance tested at 0.25V, 0ADC and 25°C.

Tolerance of inductance: 1.0uH-2.2uH: $\pm 30\%$ (N).

3.3uH-47uH: $\pm 20\%$ (M).

(2).DCR measured at 25°C.

(3). The DC current at which the inductance decreases by 30% from its initial value.

(4). The DC current that results in a 40°C temperature rise from 25°C ambient.

[Click here for QUANTITY PER REEL & PACKING INFORMATION](#)

Custom versions available upon request.

© 2019 Signal Transformer –Specification subject to change without notice. 12.19



belfuse.com/signal

128 Atlantic Avenue, Lynbrook, NY 11563
Toll Free 866-239-5777 • Tel 516-239-5777 • Fax 516-239-7208
Sales@signaltransformer.com • techhelp@signaltransformer.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Bel:

[SCNR3010-1R5](#) [SCNR3010-6R8](#) [SCNR3010-470](#) [SCNR3010-4R7](#) [SCNR3010-1R0](#) [SCNR3010-100](#) [SCNR3010-3R3](#) [SCNR3010-2R2](#) [SCNR3010-150](#) [SCNR3010-330](#) [SCNR3010-220](#)