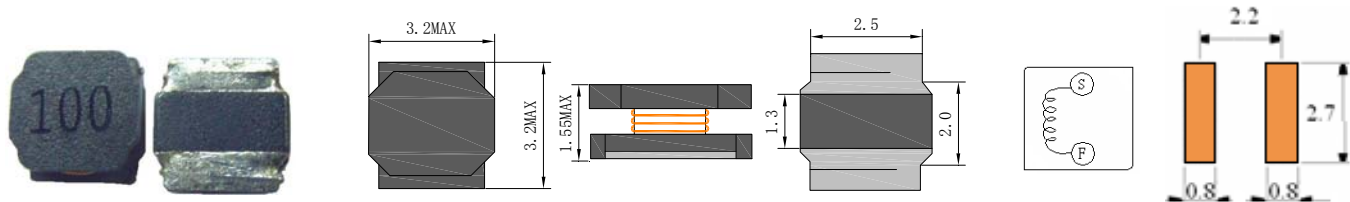


SMD POWER INDUCTORS

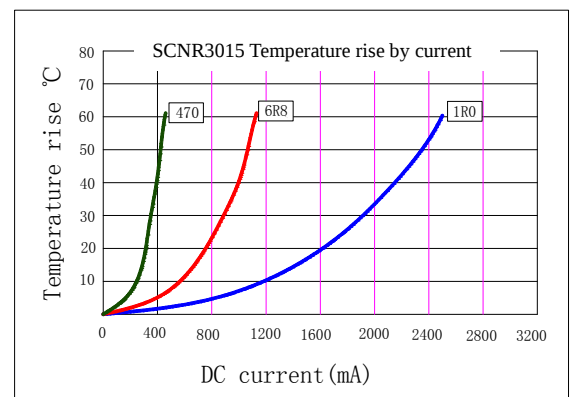
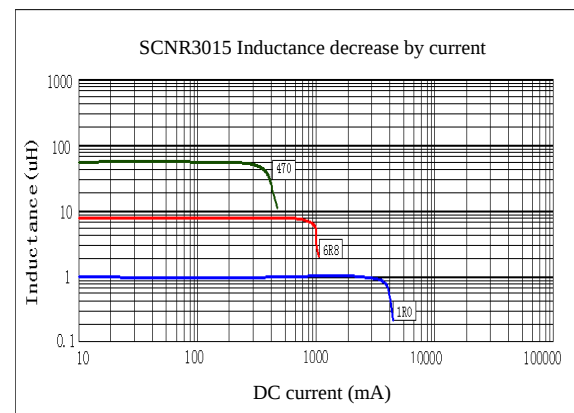


- Features

1. Open frame construction.



ELECTRICAL CHARACTERISTICS

[illegible]

(1). Inductance tested at 0.25V, 0ADC and 25°C.

Tolerance of inductance: 1.0uH-1.5uH: $\pm 30\%$ (N).

2.2uH-47uH: $\pm 20\%$ (M).

(2).DCR measured at 25°C.

(3). The DC current at which the inductance decreases by 10% from its initial value.

(4). The DC current that results in a 40°C temperature rise from 25°C ambient.

[Click here for QUANTITY PER REEL & PACKING INFORMATION](#)

Custom versions available upon request.

© 2019 Signal Transformer –Specification subject to change without notice. 12.19



belfuse.com/signal

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Bel:

[SCNR3015-1R5](#) [SCNR3015-150](#) [SCNR3015-4R7](#) [SCNR3015-2R2](#) [SCNR3015-3R3](#) [SCNR3015-100](#) [SCNR3015-1R0](#) [SCNR3015-330](#) [SCNR3015-6R8](#) [SCNR3015-220](#) [SCNR3015-470](#)