




1. Open frame construction.



SCNR4012 Inductance decrease by current

DC current (mA)	Inductance (uH) - 22uH	Inductance (uH) - 4uH	Inductance (uH) - 1R0
10	~50	~4	~1
100	~45	~3.5	~1
500	~10	~2.5	~1
1000	~1	~0.5	~0.8
2000	-	~0.1	~0.3

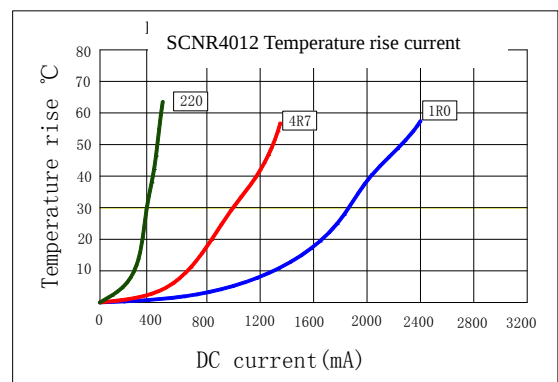

(4). The DC current that results in a 40°C temperature rise from 25°C ambient.

[Click here for QUANTITY PER REEL & PACKING INFORMATION](#)

Custom versions available upon request.

© 2019 Signal Transformer –Specification subject to change without notice. 12.19

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Bel:

[SCNR4012-470](#) [SCNR4012-1R0](#) [SCNR4012-100](#) [SCNR4012-6R8](#) [SCNR4012-220](#) [SCNR4012-1R5](#) [SCNR4012-3R3](#) [SCNR4012-150](#) [SCNR4012-330](#) [SCNR4012-4R7](#) [SCNR4012-2R2](#)