
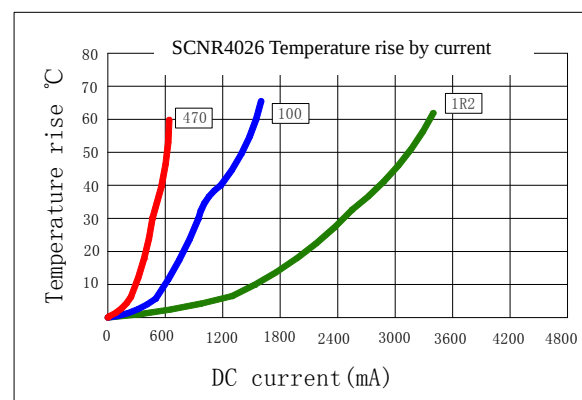


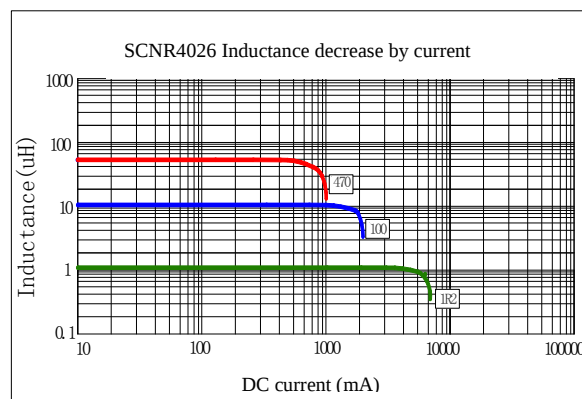

1. Open frame construction.

[illegible]

(1). Inductance tested at 0.25V, 0ADC and 25°C.

Tolerance of inductance: 1.2uH-2.3uH $\pm$ 30% (N).
3.5uH-47uH: $\pm$ 20% (M).

(2).DCR measured at 25°C.

(3).The DC current at which the inductance decreases by 30% from its initial value.

(4).The DC current that results in a 40°C temperature rise from 25°C ambient.

[Click here for QUANTITY PER REEL & PACKING INFORMATION](#)

Custom versions available upon request.

© 2019 Signal Transformer –Specification subject to change without notice. 12.19

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Bel:

[SCNR4026-470](#) [SCNR4026-330](#) [SCNR4026-150](#) [SCNR4026-4R7](#) [SCNR4026-1R2](#) [SCNR4026-6R6](#) [SCNR4026-100](#) [SCNR4026-2R3](#) [SCNR4026-3R5](#) [SCNR4026-220](#)