


SMD POWER INDUCTORS

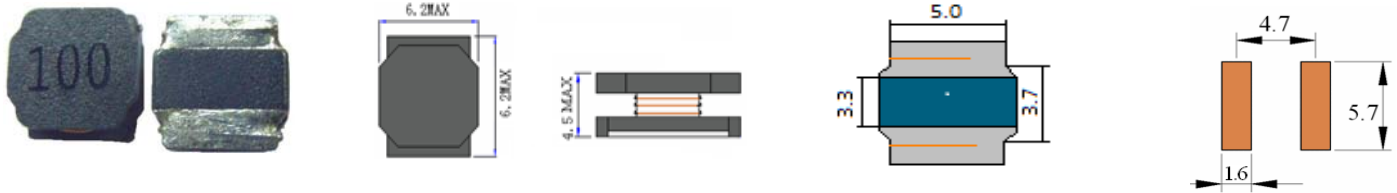

- Features

- ### 1. Open frame construction.



ELECTRICAL CHARACTERISTICS

[illegible]

(1). Inductance tested at 0.25V, 0ADC and 25°C.



Tolerance of inductance: 1.0uH-6.3uH: $\pm 30\%$ (N).

10uH-100uH: $\pm 20\%$ (M).

(2).DCR measured at 25°C.

(3). The DC current at which the inductance decreases by 10% from its initial value.

(4). The DC current that results in a 40°C temperature rise from 25°C ambient.

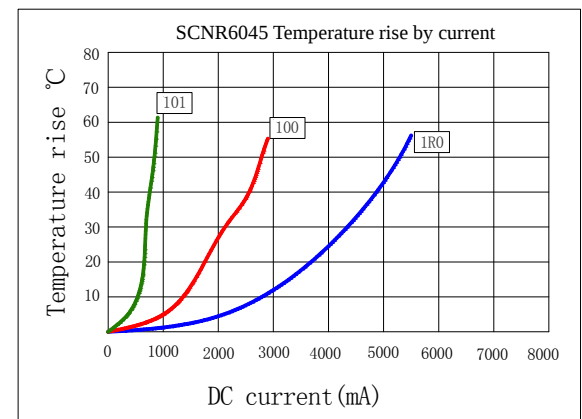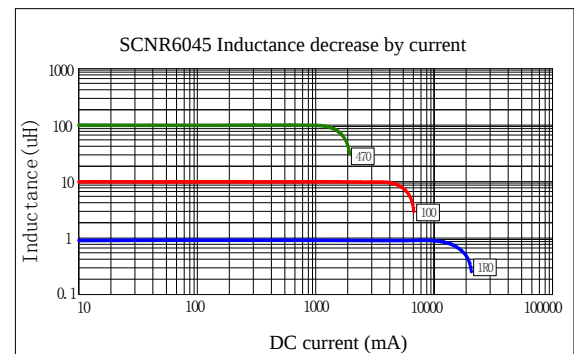

[Click here for QUANTITY PER REEL & PACKING INFORMATION](#)

Custom versions available upon request.

© 2019 Signal Transformer –Specification subject to change without notice. 12.19

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Bel:

[SCNR6045-470](#) [SCNR6045-1R0](#) [SCNR6045-1R8](#) [SCNR6045-220](#) [SCNR6045-1R3](#) [SCNR6045-6R3](#) [SCNR6045-3R0](#) [SCNR6045-4R5](#) [SCNR6045-101](#) [SCNR6045-680](#) [SCNR6045-150](#) [SCNR6045-2R3](#) [SCNR6045-330](#)
[SCNR6045-100](#)