


Semflex Bulk Cable in 25ft Packages

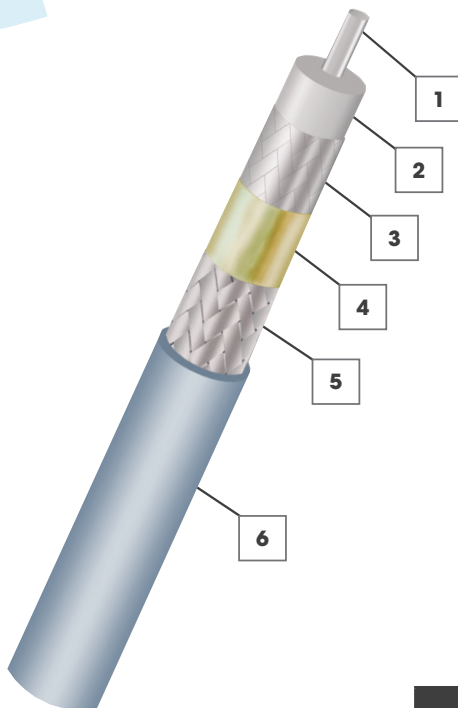

Choose from the top 9 Semflex cables that include HP120S, HP160S, HP160U, HP190S, LA190S, LA290S, SW060, SW086 and the SW110 types.

Markets

High-end RF/Microwave systems used in:

- Military
- Commercial
- Test and production lab applications

Applications

- Engineering prototyping
- Small production runs
- Custom test cables assemblies

Part Number	Description	Electrical Specs			Mechanical Specs, in.					
		Max. Freq	Insertion Loss	Inside Bend Radius	1	2	3	4	5	6
		GHz	dB/ft @ 18GHz	Min, in.	Center Conductor	Dielectric	Outer Conductor	Interlayer	Shield	Jacket
88142-L25	Cable HP120S 25 ft length	50	0.752	0.600"	0.025"	0.074"	0.080"	0.088"	0.104"	0.124"
88164-L25	Cable HP160S 25 ft length	40	0.566	0.900"	0.036"	0.106"	0.118"	0.127"	0.143"	0.160"
88327-L25	Cable HP160U 25 ft length	40	0.692	0.900"	0.034"	0.097"	0.109"	0.120"	0.136"	0.168"
88127-L25	Cable HP190S 25 ft length	28	0.379	1.100"	0.051"	0.151"	0.163"	0.172"	0.188"	0.205"
88315-L25	Cable LA190S 25 ft length	28	0.371	1.100"	0.055"	0.147"	0.158"	N/A	0.174"	0.189"
88242-L25	Cable LA290S 25 ft length	19.7	0.213	1.600"	0.089"	0.241"	0.253"	N/A	0.269"	0.292"
FSW060-EF-L25	Cable SW060 25 ft length	129	1.693	0.275"	0.011"	0.033"	0.039"	N/A	0.049"	0.060"
FSW086-EF-L25	Cable SW086 25 ft length	71	1.073	0.400"	0.020"	0.059"	0.065"	N/A	0.083"	0.091"
FSW110-EF-L25	Cable SW110 25 ft length	55	0.792	0.500"	0.025"	0.074"	0.080"	N/A	0.096"	0.118"

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Cinch Connectivity Solutions:](#)

[88142-L25](#) [88327-L25](#) [FSW086-EF-L25](#) [88164-L25](#) [88315-L25](#) [88242-L25](#) [FSW060-EF-L25](#) [88127-L25](#) [FSW110-EF-L25](#)