

Between-Series Adapters

TNC Bulkhead to SMA TNC Flange Mount to SMA

TNC Bulkhead Female Jack to SMA Male Plug

Model Number

ADT-2815-TF-SMM-02

SPECIFICATIONS

Frequency: DC - 18.0 GHz


VSWR: 1.05 @ DC-4.0 GHz

1.10 @ 4.0-8.0 GHz

1.15 @ 8.0-18.0 GHz

Impedance: 50 Ohms

Finish: Passivated Stainless Steel

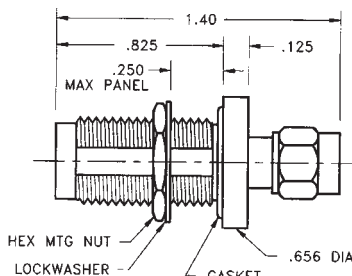

TNC Bulkhead Female Jack to SMA Female Jack

Model Number

ADT-2793-TF-SMF-02

SPECIFICATIONS

Frequency: DC - 18.0 GHz


VSWR: 1.05 @ DC-4.0 GHz

1.10 @ 4.0-8.0 GHz

1.15 @ 8.0-18.0 GHz

Impedance: 50 Ohms

Finish: Passivated Stainless Steel

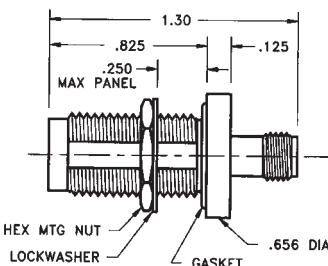

Note: A rear mounted bulkhead TNC to SMA female adapter is also available as ADT-2779-TF-SMF-02

TNC Flange Mount Female Jack to SMA Male Plug

Model Number

ADT-2689-TF-SMM-02

SPECIFICATIONS

Frequency: DC - 18.0 GHz


VSWR: 1.05 @ DC-4.0 GHz

1.10 @ 4.0-8.0 GHz

1.15 @ 8.0-18.0 GHz

Impedance: 50 Ohms

Finish: Passivated Stainless Steel

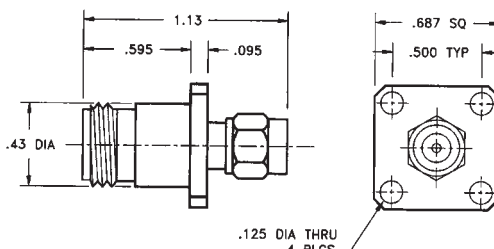

TNC Flange Mount Female Jack to SMA Female Jack

Model Number

ADT-2699-TF-SMF-02


SPECIFICATIONS

Frequency: DC - 18.0 GHz

VSWR: 1.07 + .015f GHz

Impedance: 50 Ohms

Finish: Passivated Stainless Steel

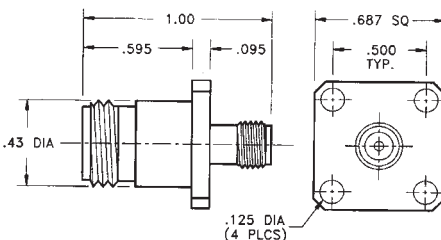

Note: Also available with four #3-56 tapped holes in flange as ADT-2699-TF-022-02

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Cinch Connectivity Solutions:](#)

[ADT-2793-TF-SMF-02](#)