

HN Male Plug to HN Female Jack

Model Number

ADT-2820-MF-HNO-02


SPECIFICATIONS

Frequency: DC - 8.0 GHz

VSWR: 1.06 @ DC - 4.0 GHz
1.10 @ 4.0 - 8.0 GHz

Impedance: 50 Ohms

Finish: Passivated Stainless Steel

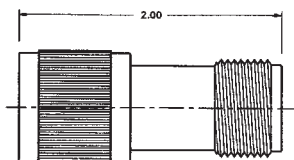

HN Female Jack to HN Female Jack

Model Number

ADT-2821-FF-HNO-02


SPECIFICATIONS

Frequency: DC - 8.0 GHz

VSWR: 1.06 @ DC - 4.0 GHz
1.10 @ 4.0 - 8.0 GHz

Impedance: 50 Ohms

Finish: Passivated Stainless Steel

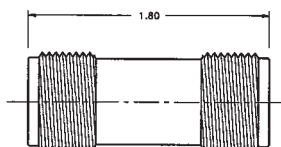

HN Male Plug to HN Male Plug

Model Number

ADT-2744-MM-HNO-02


SPECIFICATIONS

Frequency: DC - 8.0 GHz

VSWR: 1.06 @ DC - 4.0 GHz
1.10 @ 4.0 - 8.0 GHz

Impedance: 50 Ohms

Finish: Passivated Stainless Steel

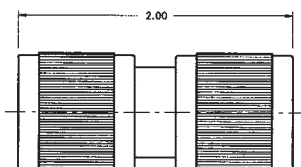

HN Female Jack to HN Female Jack - Flange Mount

Model Number

ADT-2822-FF-HNO-02


SPECIFICATIONS

Frequency: DC - 8.0 GHz

VSWR: 1.06 @ DC - 4.0 GHz
1.10 @ 4.0 - 8.0 GHz

Impedance: 50 Ohms

Finish: Passivated Stainless Steel

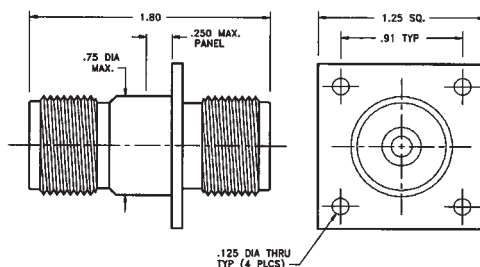

Note: Also available in bulkhead mount as ADT-2823-FF-HNO-02

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Cinch Connectivity Solutions:](#)

[ADT-2820-MF-HN0-02](#)