

### BNC Male Plug to BNC Female Jack

#### Model Number

**ADT-2828-MF-BNC-10**


#### SPECIFICATIONS

**Frequency:** DC - 4.0 GHz

**VSWR:** 1.15 @ DC - 4.0 GHz

**Impedance:** 50 Ohms

**Finish:** Nickel Plated Brass

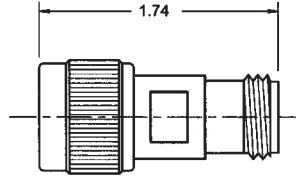

### BNC Female Jack to BNC Female Jack

#### Model Number

**ADT-2829-FF-BNC-10**


#### SPECIFICATIONS

**Frequency:** DC - 4.0 GHz

**VSWR:** 1.15 @ DC - 4.0 GHz

**Impedance:** 50 Ohms

**Finish:** Nickel Plated Brass

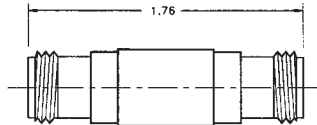

### BNC Male Plug to BNC Male Plug

#### Model Number

**ADT-2830-MM-BNC-10**


#### SPECIFICATIONS

**Frequency:** DC - 4.0 GHz

**VSWR:** 1.15 @ DC - 4.0 GHz

**Impedance:** 50 Ohms

**Finish:** Nickel Plated Brass

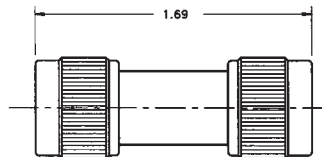

### BNC Female Jack to BNC Female Jack - Blkhd Mount

#### Model Number

**ADT-2831-FF-BNC-10**


#### SPECIFICATIONS

**Frequency:** DC - 4.0 GHz

**VSWR:** 1.15 @ DC - 4.0 GHz

**Impedance:** 50 Ohms

**Finish:** Nickel Plated Brass

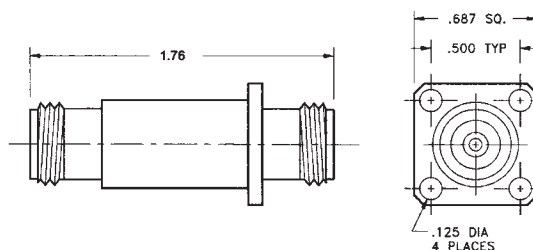

Note: Also available in .687 square flange mount as ADT-2827-FF-BNC-02

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Cinch Connectivity Solutions:](#)

[ADT-2828-MF-BNC-10](#)