


Specification Sheet

Part Number: 111-00467

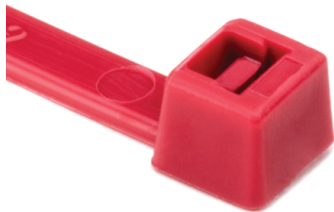

UV stabilized cable ties contain an inhibitor which prolongs the life of the tie in UV exposures

Inside serrations allow for strong grip on cables and wire bundles

Head design provides high tensile strength with very low insertion force

Bent tail ensures a quick and simple installation

Cable Tie, 15" Long, UL Rated, 50lb Tensile Strength, PA66UV, Red, 100/pkg

Article Number	111-00467
----------------	-----------

Type	T50L
------	------

Color	Red (RD)
-------	----------

Quantity Per	bag
--------------	-----

Product Description	T-Series Cable Ties feature inside serrations to provide a positive hold on wire and cable bundles. The head design guarantees high tensile strength and a low insertion force. The bent tail design allows quick and simple installations by hand. For high-volume applications, tensioning tools are available to ensure consistent and safe installation.
---------------------	--

Short Description	Cable Tie, 15" Long, UL Rated, 50lb Tensile Strength, PA66UV, Red, 100/pkg
-------------------	--

Global Part Name	T50L-PA66UV-RD
------------------	----------------

Minimum Tensile Strength (Imperial)	50.0
-------------------------------------	------

Minimum Tensile Strength (Metric)	225.0
-----------------------------------	-------

Length L (Imperial)	15.0
---------------------	------

Length L (Metric)	390.0
-------------------	-------

Identification Plate Position	none
-------------------------------	------

Releasable Closure	No
--------------------	----

Tie Closure	plastic pawl
-------------	--------------

Variant	Inside Serrated
---------	-----------------

Width W (Imperial)	0.19
--------------------	------

Width W (Metric)	4.8
------------------	-----

Bundle Diameter Min (Imperial)	0.06
--------------------------------	------

Bundle Diameter Min (Metric)	1.5
------------------------------	-----

Bundle Diameter Max (Imperial)	4.33
--------------------------------	------

Bundle Diameter Max (Metric)	110.0
------------------------------	-------

Thickness T (Metric)	1.4
----------------------	-----

Material	Polyamide 6.6 UV-resistant (PA66UV)
Material Shortcut	PA66UV
Flammability	UL 94 V-2
Halogen Free	Yes
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
ROHS Compliant	Yes
Certification/Specification	UL-ZODZ2.E64139
UL Recognized (US)	Yes
UL Recognized (US and Canada)	Yes
Package Quantity (Imperial)	100
Package Quantity (Metric)	100
Customs Number	3926909988

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[111-00467](#)