


Specification Sheet

Part Number: T150LL0K2

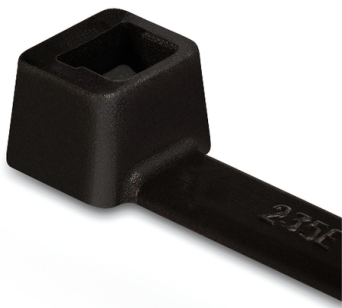

- Engineered and manufactured for maximum performance and quality.
- Made from 100% high-quality plastic to ensure efficient recycling.
- Inside serration for a strong grip onto bundles.
- Easy application either manually or with a tensioning tool.

Heavy Duty Cable Tie, 36" Long, UL Rated, 175lb Tensile Strength, PA66, Black, 50/pkg

Article Number	111-01327
Type	T150LL
Color	Black (BK)
Quantity Per	bag
Product Description	HellermannTyton heavy duty cable ties offer a higher tensile strength for heavy load applications. The head design guarantees high tensile strength, as well as a low insertion force. For high volume applications, tensioning tools are available to ensure consistent and safe installation.
Short Description	Heavy Duty Cable Tie, 36" Long, UL Rated, 175lb Tensile Strength, PA66, Black, 50/pkg
Global Part Name	T150LL-PA66-BK

Minimum Tensile Strength (Imperial)	175.0
Minimum Tensile Strength (Metric)	780
Length L (Imperial)	36.0
Length L (Metric)	925.0
Identification Plate Position	none
Releasable Closure	No
Tie Closure	plastic pawl
Variant	Inside Serrated
Width W (Imperial)	0.35
Width W (Metric)	8.9
Bundle Diameter Min (Imperial)	0.31
Bundle Diameter Min (Metric)	8.0
Bundle Diameter Max (Imperial)	10.8
Bundle Diameter Max (Metric)	275.0
Material	Polyamide 6.6 (PA66)

Material Shortcut	PA66
Flammability	UL 94 V-2
Halogen Free	Yes
UV Resistant (Yes/No)	No
Plenum Rating	AH-2
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	No
ROHS Compliant	Yes
UL Recognized (US)	Yes
UL Listed (US and Canada)	Yes
UL Recognized (US and Canada)	Yes
UL Listed (US)	Yes
Package Quantity (Imperial)	50
Package Quantity (Metric)	50
Customs Number	3926909988

About HellermannTyton

HellermannTyton is a global manufacturer of cable management and identification solutions for automotive, solar, electrical, construction, industrial automation, broadband and other OEM markets. The company's integrated approach to product design, sustainability, production, quality assurance and delivery is optimized to benefit local and global customers. HellermannTyton operates in 39 countries, with North American headquarters in Milwaukee, Wisconsin. (www.hellermann.tyton.com).

© 2024 HellermannTyton. All Rights Reserved.

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Disclaimer](#)

[Terms and Conditions](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[T150LL0K2](#)