


Specification Sheet

Part Number: 151-00623

Clip can be installed by hand – no need for hardware or tools.

Design provides low insertion and high extraction force, for simple, secure performance.

Clip keeps bundle away from areas that could cause damage due to rubbing.

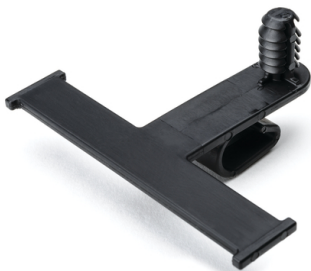

Standoff Bundling Clip, 2.2" Long, 0.03 - 0.22" Panel Thickness, PA66HIRHSUV, Black, 1500/box

Article Number	151-00623
Type	SOCHFT6
Color	Black (BK)
Quantity Per	box
Product Description	Standoff bundling clips provide a straightforward way to secure cable bundles, hoses or pipes. The bundle fastens to the tape bar using tape or cable ties. Multiple orientations allow tape clips to be used with a wide range of panel thicknesses and hole diameters. Standoff keeps bundles away from mounting area to prevent them from damage due to rubbing.
Short Description	Standoff Bundling Clip, 2.2" Long, 0.03 - 0.22" Panel Thickness, PA66HIRHSUV, Black, 1500/box

Global Part Name	SOCHFT6-PA66HIRHSUV-BK
------------------	------------------------

Length L (Imperial)	2.2
---------------------	-----

Length L (Metric)	56.0
-------------------	------

Offset Length (Imperial)	1.28
--------------------------	------

Offset Length (Metric)	32.5
------------------------	------

Fixation Method	Fir Tree
-----------------	----------

Bundle Diameter Min (Metric)	7.0
------------------------------	-----

Bundle Diameter Max (Metric)	7.0
------------------------------	-----

Height H (Imperial)	0.9
---------------------	-----

Height H (Metric)	22.5
-------------------	------

Panel Thickness Min (Imperial)	0.03
--------------------------------	------

Panel Thickness Max (Imperial)	0.22
--------------------------------	------

Panel Thickness Min (Metric)	0.7
------------------------------	-----

Panel Thickness Max (Metric)	5.5
------------------------------	-----

Mounting Hole Diameter D (Imperial)	0.25 - 0.27
-------------------------------------	-------------

Mounting Hole Diameter D (Metric)	6.35 - 7.0 mm
-----------------------------------	---------------

Mounting Hole Diameter D Min (Imperial) 0.25

Mounting Hole Diameter D Max (Imperial) 0.28

Mounting Hole Diameter D Max (Metric) 7.0

Material Polyamide 6.6 high impact modified, heat and UV stabilized (PA66HIRHSUV)

Material Shortcut PA66HIRHSUV

Flammability UL 94 HB

UV Resistant (Yes/No) Yes

Operating Temperature -40°F to +221°F (-40°C to +105°C)

Reach Compliant (Article 33) Yes

ROHS Compliant Yes

Package Quantity (Imperial) 1500

Package Quantity (Metric) 1500

Customs Number 3926909988

About HellermannTyton

HellermannTyton is a global manufacturer of cable management and identification solutions for automotive, solar, electrical, construction, industrial automation, broadband and other OEM markets. The company's integrated approach to product design, sustainability, production, quality assurance and delivery is optimized to benefit local and global customers. HellermannTyton operates in 40 countries, with North American headquarters in Milwaukee, Wisconsin. (www.hellermann.tyton.com).

© 2024 HellermannTyton. All Rights Reserved.

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Disclaimer](#)

[Terms and Conditions](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[151-00623](#)