


Specification Sheet

Part Number: 151-00903

Clip can be installed by hand – no need for hardware or tools.

Design provides low insertion and high extraction force, for simple, secure performance.

Clip keeps bundle away from areas that could cause damage due to rubbing.

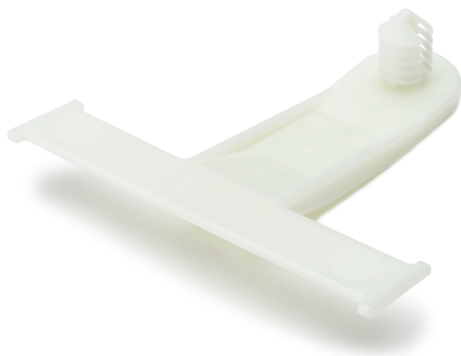

Standoff Bundling Clip, 2.3" Long, 0.02 - 0.23" Panel Thickness, PA66HIRHS, Natural, 3000/box

Article Number

151-00903

Type

SOC10FT6LG

Color

Natural (NA)

Quantity Per

box

Product Description

Bundling clips are designed to provide simple and easy methods of securing cable bundles, hoses, or pipes. They are fastened onto the tape bar using bundle or cable ties. The different fixing orientations allow tape clips to be used with a wide range of panel thicknesses and hole diameters. Standard bundling clips are available as well as standoff and stud mount versions.

Short Description

Standoff Bundling Clip, 2.3" Long, 0.02 - 0.23" Panel Thickness, PA66HIRHS, Natural, 3000/box

Global Part Name	SOC10FT6LG-PA66HIRHS-NA
Length L (Imperial)	2.3
Length L (Metric)	58.0
Offset Length (Imperial)	1.71
Offset Length (Metric)	43.35
Fixation Method	Fir Tree
Width W (Imperial)	0.6
Width W (Metric)	16.0
Height H (Imperial)	0.60
Height H (Metric)	14.50
Panel Thickness Min (Imperial)	0.02
Panel Thickness Max (Imperial)	0.23
Panel Thickness Min (Metric)	0.6
Panel Thickness Max (Metric)	5.75
Mounting Hole Diameter D (Imperial)	0.24 - 0.27 ";0.24 - 0.26 (hexagonal)
Mounting Hole Diameter D (Metric)	6.1 - 6.6 mm (hexagonal) 6.1 - 6.9 mm

Mounting Hole Diameter D Min (Imperial) 0.24

Mounting Hole Diameter D Max (Imperial) 0.27

Mounting Hole Diameter D Max (Metric) 6.9

Material Polyamide 6.6, high impact modified, heat stabilized (PA66HIRHS)

Material Shortcut PA66HIRHS

Flammability UL 94 HB

UV Resistant (Yes/No) No

Use Conditions For Indoor Use Only

Operating Temperature -40°F to +230°F (-40°C to +110°C)

Reach Compliant (Article 33) Yes

ROHS Compliant Yes

Package Quantity (Imperial) 3000

Package Quantity (Metric) 3000

Customs Number 3926909988

© 2024 HellermannTyton. All Rights Reserved.

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Disclaimer](#)

[Terms and Conditions](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[151-00903](#)