


Specification Sheet

Part Number: 151-00932

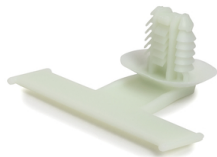

Clip can be installed by hand – no need for hardware or tools.

Design provides low insertion and high extraction force, for simple, secure performance.

Clip keeps bundle away from areas that could cause damage due to rubbing.

Standoff Bundling Clip, 1.97" Long, 0.02 - 0.27" Panel Thickness, PA66HIRHS, Natural, 3000/carton

Article Number	151-00932
----------------	-----------

Type	SOC11FTOVAL
------	-------------

Color	Natural (NA)
-------	--------------

Quantity Per	carton
--------------	--------

Product Description	Standoff bundling clips provide a straightforward way to secure cable bundles, hoses or pipes. The bundle fastens to the tape bar using tape or cable ties. Multiple orientations allow tape clips to be used with a wide range of panel thicknesses and hole diameters. Standoff keeps bundles away from mounting area to prevent them from damage due to rubbing.
---------------------	---

Short Description	Standoff Bundling Clip, 1.97" Long, 0.02 - 0.27" Panel Thickness, PA66HIRHS, Natural, 3000/carton
-------------------	---

Global Part Name	SOC11FTOVAL-PA66HIRHS-NA
Length L (Imperial)	1.97
Length L (Metric)	50.0
Offset Length (Imperial)	0.79
Offset Length (Metric)	20.0
Fixation Method	Fir Tree for oval holes
Width W (Imperial)	0.37
Width W (Metric)	9.5
Height H (Imperial)	0.79
Height H (Metric)	20.1
Panel Thickness Min (Imperial)	0.02
Panel Thickness Max (Imperial)	0.27
Panel Thickness Min (Metric)	0.6
Panel Thickness Max (Metric)	6.75
Mounting Hole Diameter D (Imperial)	0.24 x 0.48 ";0.25 x 0.50 ";0.25 x 0.50 ";0.27 x 0.47
Mounting Hole Diameter D (Metric)	6.5 x 13.0 mm 6.2 x 12.2 mm 6.5 x 12.5 mm 7.0 x 12.0 mm

Mounting Hole Diameter D Min (Imperial) 0.24

Mounting Hole Diameter D Max (Imperial) 0.50

Mounting Hole Diameter D Max (Metric) 13.0

Material Polyamide 6.6, high impact modified, heat stabilized (PA66HIRHS)

Material Shortcut PA66HIRHS

Flammability UL 94 HB

Halogen Free Yes

UV Resistant (Yes/No) No

Operating Temperature -40°F to +230°F (-40°C to +110°C)

Reach Compliant (Article 33) Yes

ROHS Compliant Yes

Package Quantity (Imperial) 3000

Package Quantity (Metric) 3000

Customs Number 3926909988

About HellermannTyton

HellermannTyton is a global manufacturer of cable management and identification solutions for automotive, solar, electrical, construction, industrial automation, broadband and other OEM markets. The company's integrated approach to product design, sustainability, production, quality assurance and delivery is optimized to benefit local and global customers. HellermannTyton operates in 40 countries, with North American headquarters in Milwaukee, Wisconsin. (www.hellermann.tyton.com).

© 2024 HellermannTyton. All Rights Reserved.

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Disclaimer](#)

[Terms and Conditions](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[151-00932](#)