


Specification Sheet

Part Number: 151-01117

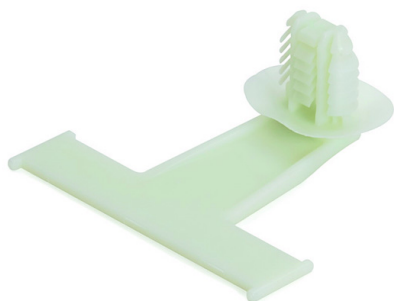

Clip can be installed by hand – no need for hardware or tools. Design provides low insertion and high extraction force, for simple, secure performance.

Clip keeps bundle away from areas that could cause damage due to rubbing.

Standoff Bundling Clip, 1.97" Long, Panel Thickness 0.02–0.27", PA66HIRHSUV, Black, 1500/carton

Article Number	151-01117
-----------------------	-----------

Type	SOC12FTOVAL
-------------	-------------

Color	Black (BK)
--------------	------------

Quantity Per	carton
---------------------	--------

Product Description	Standoff bundling clips provide a straightforward way to secure cable bundles, hoses or pipes. The bundle fastens to the tape bar using tape or cable ties. Multiple orientations allow tape clips to be used with a wide range of panel thicknesses and hole diameters. Standoff keeps bundles away from mounting area to prevent them from damage due to rubbing.
----------------------------	---

Short Description	Standoff Bundling Clip, 1.97" Long, Panel Thickness 0.02–0.27", PA66HIRHSUV, Black, 1500/carton
--------------------------	---

Global Part Name

SOC12FTOVAL-PA66HIRHSUV-BK

Length L (Imperial) 1.97**Length L (Metric)** 50.0**Offset Length (Imperial)** 1.26**Offset Length (Metric)** 32.0**Fixation Method** Fir Tree for oval holes**Height H (Imperial)** 0.79**Height H (Metric)** 20.0**Panel Thickness Min (Imperial)** 0.023**Panel Thickness Max (Imperial)** 0.27**Panel Thickness Min (Metric)** 0.6**Panel Thickness Max (Metric)** 6.75**Mounting Hole Diameter D (Imperial)** 0.24 x 0.48 " 0.26 x 0.50 " 0.26 x 0.51 " 0.28 x 0.47**Mounting Hole Diameter D (Metric)** 6.2 x 12.2 mm 6.5 x 12.5 mm 7.0 x 12.0 mm 6.5 x 13.0 mm**Mounting Hole Diameter D Min (Imperial)** 0.24**Mounting Hole Diameter D Max (Imperial)** 0.51

Mounting Hole Diameter D Max (Metric) 13.0

Material Polyamide 6.6 high impact modified, heat and UV stabilized (PA66HIRHSUV)

Material Shortcut PA66HIRHSUV

Operating Temperature -40°F to +221°F (-40°C to +105°C)

Reach Compliant (Article 33) Yes

ROHS Compliant Yes

Package Quantity (Imperial) 1500

Package Quantity (Metric) 1500

Customs Number 3926909988

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[151-01117](#)