


Specification Sheet

Part Number: 151-01170

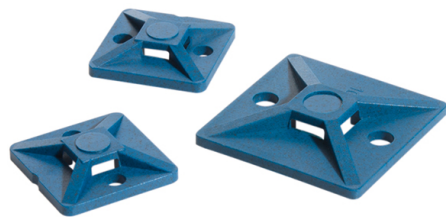

Designed for use with MCT18 - MCT120 cable ties to provide stability when securing bundles.
Simple to install with a screw or rivet.
Metal content dispersed throughout mount ensures identification by metal detectors and X-ray machines.
Industry standard blue color assists with visual detection and reduces the risk of contamination.

Metal Content Cable Tie Mount, 1.1" x 1.1", .33" Max Tie Width, PA66MP, Blue, 100/pkg

Article Number	151-01170
Type	MCMB4
Color	Blue (BU)
Quantity Per	bag
Product Description	The MCMB4 mounts are for use with HellermannTyton MCT18 - MCT120 Series cable ties to provide stability when securing bundles. The Metal Content Mount is specifically designed for the food, beverage and pharmaceutical processing industries to meet the safety standards set by the Hazardous Analysis of Critical Control Point (HACCP). The mount is nylon-based with metal content dispersed throughout allowing for the part to be identified by metal detectors or X-ray inspections, reducing the risk of contamination.

Short Description	Metal Content Cable Tie Mount, 1.1" x 1.1", .33" Max Tie Width, PA66MP, Blue, 100/pkg
Global Part Name	MCMB4-PA66MP-BU
Length L (Imperial)	1.10
Length L (Metric)	28.0
Fixation Method	Screw Mounting and Rivet
Width W (Imperial)	1.1
Width W (Metric)	28.0
Cable Ties	MCT18 - MCT50
Height H (Imperial)	0.19
Height H (Metric)	4.7
Cable Tie Width Max (Imperial)	0.19
Cable Tie Width Max (Metric)	4.7
Mounting Hole Diameter D (Imperial)	0.16
Mounting Hole Diameter D (Metric)	4.0 mm
Mounting Hole Diameter D Min (Imperial)	0.16

Mounting Hole Diameter D Max (Imperial) 0.16

Mounting Hole Diameter D Max (Metric) 4.0

Mounting Hole Centers (Imperial) 0.79

Material Polyamide 6.6, with metal particles (PA66MP)

Material Shortcut PA66MP

Flammability UL 94 HB

Halogen Free Yes

Operating Temperature -40°F to +185°F (-40°C to +85°C)

Reach Compliant (Article 33) Yes

ROHS Compliant Yes

Package Quantity (Imperial) 100

Package Quantity (Metric) 100

Customs Number 3926909988

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[151-01170](#)