

Specification Sheet

Part Number: 151-01632


For use with HellermannTyton T18 - T50 cable ties to provide stability when securing bundles.

4-way opening allows cable ties to be installed parallel or perpendicular to bundles.

The high-heat, high-bond adhesive is ideal for outdoor applications, with a static load weight of 1.1 lb.

Two predrilled holes extend mounting options and solutions.

Extended adhesive liner is easy to remove quickly.

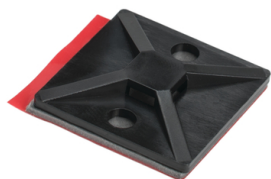

High Heat High Bond Acrylic Adhesive Base, 1.12 x 1.12", Use T18-T50 Tie, PA66HIRHSUV, Black, 500/pkg

Article Number	151-01632
----------------	-----------

Type	MB4A
------	------

Color	Black (BK)
-------	------------

Quantity Per	bag
--------------	-----

Product Description	MB4A4 adhesive mounts are for use with HellermannTyton T18 - T50 Series cable ties to provide stability when securing bundles. The high-heat, high-bond acrylic adhesive-backed mounts can be used to secure a bundle and have two predrilled holes to extend mounting options.
---------------------	---

Short Description	High Heat High Bond Acrylic Adhesive Base, 1.12 x 1.12", Use T18-T50 Tie, PA66HIRHSUV, Black, 500/pkg
Global Part Name	MB4A-PA66HIRHSUV-BK
Length L (Imperial)	1.12
Length L (Metric)	28.5
Fixation Method	Adhesive
Width W (Imperial)	1.12
Width W (Metric)	28.5
Cable Ties	T18 - T50
Height H (Imperial)	.22
Height H (Metric)	5.6
Cable Tie Width Max (Imperial)	0.18
Cable Tie Width Max (Metric)	4.6
Mounting Hole Diameter D (Imperial)	0.18
Mounting Hole Diameter D (Metric)	4.6 mm
Mounting Hole Centers (Imperial)	0.8

Material	Polyamide 6.6 high impact modified, heat and UV stabilized (PA66HIRHSUV)
Material Shortcut	PA66HIRHSUV
Adhesive	Acrylic foam
Flammability	UL 94 HB
UV Resistant (Yes/No)	Yes
Adhesive Operating Temperature	-40°F to +176°F (-40°C to +80°C)
Operating Temperature	-40°F to +221°F (-40°C to +105°C)
Reach Compliant (Article 33)	No
ROHS Compliant	Yes
Package Quantity (Imperial)	500
Package Quantity (Metric)	500
Customs Number	3926909988

About HellermannTyton

HellermannTyton is a global manufacturer of cable management and identification solutions for automotive, solar, electrical, construction, industrial automation, broadband and other OEM markets. The company's integrated approach to product design, sustainability, production, quality assurance and delivery is optimized to benefit local and global customers. HellermannTyton operates in 40 countries, with North American headquarters in Milwaukee, Wisconsin.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[151-01632](#)