


Specification Sheet

Part Number: 151-02457

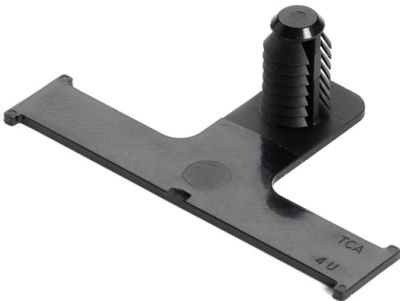

Multiple available orientations allow tape clips to be used with a wide range of panel thicknesses and hole diameters.

Clip can be installed by hand – no need for hardware or tools.

Design provides low insertion and high extraction force, for simple, secure performance.

Clip keeps bundle away from areas that could cause damage due to rubbing.

Standoff Bundling Clip, 2.36" Long, Panel Thickness 0.02–0.23", PA66HIRHS, Black, 5,000/carton

|                     |                                                                                                        |
|---------------------|--------------------------------------------------------------------------------------------------------|
| Article Number      | 151-02457                                                                                              |
| Type                | SOBC25FT8                                                                                              |
| Color               | Black (BK)                                                                                             |
| Quantity Per        | carton                                                                                                 |
| Product Description | Tape clips are designed to provide simple and easy methods of securing cable bundles, hoses, or pipes. |
| Short Description   | Standoff Bundling Clip, 2.36" Long, Panel Thickness 0.02–0.23", PA66HIRHS, Black, 5,000/carton         |
| Global Part Name    | SOBC25FT8-PA66HIRHSUV-BK                                                                               |

|                                            |                                                                          |
|--------------------------------------------|--------------------------------------------------------------------------|
| <b>Length L (Imperial)</b>                 | 2.36                                                                     |
| <b>Length L (Metric)</b>                   | 60.0                                                                     |
| <b>Offset Length (Metric)</b>              | 25.3                                                                     |
| <b>Width W (Imperial)</b>                  | 1.377                                                                    |
| <b>Width W (Metric)</b>                    | 35.0                                                                     |
| <b>Height H (Imperial)</b>                 | 0.7                                                                      |
| <b>Height H (Metric)</b>                   | 17.9                                                                     |
| <b>Mounting Hole Diameter D (Imperial)</b> | 0.314                                                                    |
| <b>Mounting Hole Diameter D (Metric)</b>   | 8.0 mm                                                                   |
| <b>Material</b>                            | Polyamide 6.6 high impact modified, heat and UV stabilized (PA66HIRHSUV) |
| <b>Material Shortcut</b>                   | PA66HIRHSUV                                                              |
| <b>Flammability</b>                        | UL 94 HB                                                                 |
| <b>Operating Temperature</b>               | -40°F to +230°F (-40°C to +110°C)                                        |

|                                    |            |
|------------------------------------|------------|
| <b>Package Quantity (Imperial)</b> | 5000       |
| <b>Package Quantity (Metric)</b>   | 5000       |
| <b>Customs Number</b>              | 3926909988 |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[151-02457](#)