

## Specification Sheet

Part Number: 151-03038


One-piece ratchet closure allows for easy installation during pre- or final assembly.

Easy release feature simplifies quick adjustments and maintenance.

Impact modified, heat and UV stabilized PA66 provides long-term durability, indoors and out.

Zinc-plated steel mounting plate tolerates high torque and is treated to resist chemicals and salt spray.

Straight, 180° mounting plate is ideal for applications requiring a flush mount set off from the mounting hole.

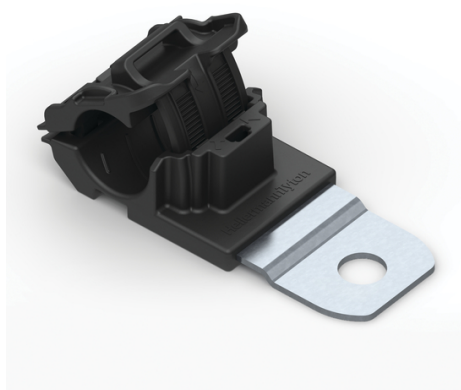

Ratchet P-Clamp, 0.50 - 0.77" Bundle Dia, 180° Short, 0.26" Hole Dia, PA66HIRHSUV/ST/ZN, Black, 20/bag

Article Number	151-03038
Type	RCB180SM6
Color	Black (BK)
Quantity Per	bag

<b>Product Description</b>	The Ratchet P-Clamp family offers versatility when managing wires, cables and hoses. The robust design and durable materials make it ideal for heavy duty applications, both indoors and out. The one-piece adjustable clamp can be closed by hand to the desired diameter. The release feature provides easy and nondestructive removal of cables simply by using a flat-head screwdriver. This nondestructive release allows the clamp to be reused without removing or replacing any bolts or screws.
<b>Short Description</b>	Ratchet P-Clamp, 0.50 - 0.77" Bundle Dia, 180° Short, 0.26" Hole Dia, PA66HIRHSUV/ST/ZN, Black, 20/bag
<b>Global Part Name</b>	RCB180SM6-PA66HIRHSUV/ST/ZN-BK
<b>Minimum Tensile Strength (Imperial)</b>	100.0
<b>Minimum Tensile Strength (Metric)</b>	445.0
<b>Length L (Imperial)</b>	4.57
<b>Length L (Metric)</b>	116.2
<b>Fixation Method</b>	Screw Mounting
<b>Variant</b>	Short
<b>Width W (Imperial)</b>	1.37
<b>Width W (Metric)</b>	34.9
<b>Bundle Diameter Min (Imperial)</b>	0.5
<b>Bundle Diameter Min (Metric)</b>	12.7

<b>Bundle Diameter Max (Imperial)</b>	0.77
<b>Bundle Diameter Max (Metric)</b>	19.5
<b>Mounting Hole Diameter D (Imperial)</b>	0.256
<b>Mounting Hole Diameter D (Metric)</b>	6.5 mm
<b>Stud Diameter (Metric)</b>	M6
<b>Mounting Hole Centers (Imperial)</b>	2.08
<b>Material</b>	Polyamide 6.6 high impact modified, heat and UV stabilized (PA66HIRHSUV) Steel (ST) Zinc plated (ZN)
<b>Material Shortcut</b>	PA66HIRHSUV ZN ST
<b>Flammability</b>	UL 94 HB
<b>Halogen Free</b>	Yes
<b>UV Resistant (Yes/No)</b>	Yes
<b>Operating Temperature</b>	-40°F to +221°F (-40°C to +105°C)
<b>ROHS Compliant</b>	Yes
<b>UL Listed (US and Canada)</b>	Yes
<b>UL Listed (US)</b>	Yes

<b>Package Quantity (Imperial)</b>	20
------------------------------------	----

<b>Package Quantity (Metric)</b>	20
----------------------------------	----

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[151-03038](#)