

Specification Sheet

Part Number: MB3A10M4


For use with HellermannTyton T18 - T30 cable ties to provide stability when securing bundles.

4-way opening allows cable ties to be installed parallel or perpendicular to bundles.

The rubber-based adhesive is an economical choice ideal for indoor applications, with a static load weight of 0.6 lb.

Two predrilled holes extend mounting options and solutions.

Extended adhesive liner is easy to remove quickly.

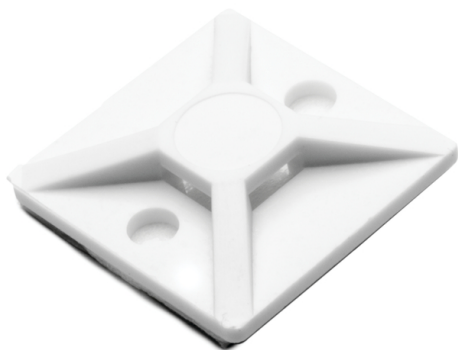

Rubber Adhesive Cable Tie Mount, 0.75 x 0.75", Use With T18-T30 Cable Tie, PA66, White, 1000/pkg

Article Number	151-28721
----------------	-----------

Type	MB3A
------	------

Color	White (WH)
-------	------------

Quantity Per	bag
--------------	-----

Product Description	MB3A adhesive mounts are for use with HellermannTyton T18 - T30 Series cable ties to provide stability when securing bundles. The rubber adhesive-backed mounts can be used to secure a bundle and have two predrilled holes to extend mounting options.
---------------------	--

Short Description	Rubber Adhesive Cable Tie Mount, 0.75 x 0.75", Use With T18-T30 Cable Tie, PA66, White, 1000/pkg
Global Part Name	MB3A-PA66-WH
Length L (Imperial)	0.75
Length L (Metric)	19.0
Fixation Method	Adhesive
Width W (Imperial)	0.75
Width W (Metric)	19.0
Cable Ties	T18 - T30
Height H (Imperial)	.18
Height H (Metric)	4.6
Cable Tie Width Max (Imperial)	0.14
Cable Tie Width Max (Metric)	3.6
Mounting Hole Diameter D (Imperial)	0.12
Mounting Hole Diameter D (Metric)	3.0 mm
Mounting Hole Centers (Imperial)	0.52

Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66
Adhesive	Synthetic rubber with base of polyethylene foam
Flammability	UL 94 V-2 (excluding adhesive)
UV Resistant (Yes/No)	No
Adhesive Operating Temperature	0°F to +150°F (-18 °C to +66 °C)
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	No
ROHS Compliant	Yes
Package Quantity (Imperial)	1000
Package Quantity (Metric)	1000
Customs Number	3926909988

About HellermannTyton

HellermannTyton is a global manufacturer of cable management and identification solutions for automotive, solar, electrical, construction, industrial automation, broadband and other OEM markets. The company's integrated approach to product design, sustainability, production, quality assurance and delivery is optimized to benefit local and global customers. HellermannTyton operates in 40 countries, with North American headquarters in Milwaukee, Wisconsin. (www.hellermann.tyton.com).

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[MB3A10M4](#)