


Specification Sheet

Part Number: MB4SH10C2

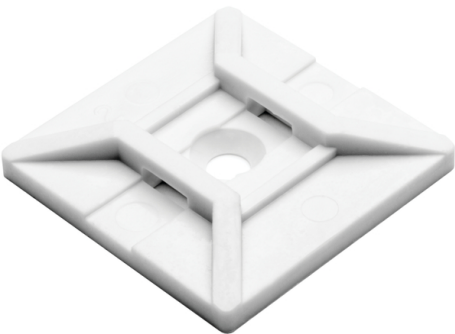

- Compact size fits most mounting applications.
- Simple to install with a screw or rivet.
- Single hole attachment with two-way entry for cable tie.

Screw Mount Cable Tie Base, 1.12 x 1.12", 0.18" Max Tie Width, 0.15" Hole Dia, PA66, White, 100/pkg

Article Number	151-29104
Type	MB4SH
Color	White (WH)
Quantity Per	pack
Product Description	These cable tie mounts are compact in size. They are designed for simple yet robust installation. They pair with a cable tie for mounting applications including telecom equipment, switchgear and control cabinets.
Short Description	Screw Mount Cable Tie Base, 1.12 x 1.12", 0.18" Max Tie Width, 0.15" Hole Dia, PA66, White, 100/pkg
Global Part Name	MB4SH-PA66-WH

Length L (Imperial)	1.12
Length L (Metric)	28.3
Fixation Method	Screw Mount
Width W (Imperial)	1.12
Width W (Metric)	28.3
Cable Ties	T18 - T50
Height H (Imperial)	.20
Height H (Metric)	5.10
Cable Tie Width Max (Imperial)	0.18
Cable Tie Width Max (Metric)	4.6
Mounting Hole Diameter D (Imperial)	0.15 "
Mounting Hole Diameter D (Metric)	3.9 mm
Mounting Hole Diameter D Max (Metric)	3.9
Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66

Flammability	UL 94 V-2
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Certification/Specification	UL
UL Recognized (US)	Yes
UL Recognized (US and Canada)	Yes
Package Quantity (Imperial)	100
Package Quantity (Metric)	100
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
 Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[MB4SH10C2](#)