


Specification Sheet

Part Number: 157-00287

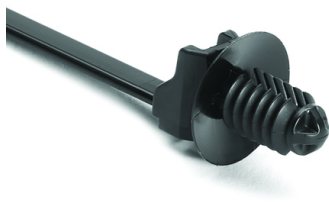

All-in-one bundling and fastening solution reduces costs and assembly time.

Disc feature provides anti-rattle protection in high-vibration applications.

1-Pc Cable Tie/Fir Tree Mount with Disc, 6.5"L, 0.25 - 0.28" Mounting Hole, PA66HS, Black, 4000/carton

Article Number	157-00287
----------------	-----------

Type	T50SOSFT6.5LG-E4X
------	-------------------

Color	Black (BK)
-------	------------

Quantity Per	bag
--------------	-----

Product Description	One-piece mounting ties offer a complete solution by both bundling and mounting wires, cables and tubes. The fir tree mount provides low insertion force with a high extraction force. Outside serrations on the cable tie leave a smooth interior surface that's gentler on sensitive wire insulation. The unique head design allows the cable tie to firmly hold bundles as small as .06" diameter. The disc offers added protection against debris.
---------------------	--

Short Description	1-Pc Cable Tie/Fir Tree Mount with Disc, 6.5"L, 0.25 - 0.28" Mounting Hole, PA66HS, Black, 4000/carton
-------------------	--

Global Part Name	T50SOSFT6.5LG-E4X-PA66HS-BK
------------------	-----------------------------

Minimum Tensile Strength (Imperial)	50.0
-------------------------------------	------

Minimum Tensile Strength (Metric)	225.0
-----------------------------------	-------

Length L (Imperial)	6.5
---------------------	-----

Length L (Metric)	165.0
-------------------	-------

Fixation Method	Fir Tree
-----------------	----------

Identification Plate Position	none
-------------------------------	------

Releasable Closure	No
--------------------	----

Tie Closure	plastic pawl
-------------	--------------

Width W (Imperial)	0.18
--------------------	------

Width W (Metric)	4.6
------------------	-----

Bundle Diameter Min (Imperial)	0.04
--------------------------------	------

Bundle Diameter Min (Metric)	1.0
------------------------------	-----

Bundle Diameter Max (Imperial)	1.38
--------------------------------	------

Bundle Diameter Max (Metric)	35.0
------------------------------	------

Thickness T (Imperial)	0.05
------------------------	------

Thickness T (Metric)	1.3
Panel Thickness Min (Imperial)	0.03
Panel Thickness Max (Imperial)	0.28
Panel Thickness Min (Metric)	0.7
Panel Thickness Max (Metric)	7.0
Mounting Hole Diameter D (Imperial)	0.25 - 0.28
Mounting Hole Diameter D (Metric)	6.3 - 7.0 mm
Mounting Hole Diameter D Min (Imperial)	0.25
Mounting Hole Diameter D Max (Imperial)	0.28
Mounting Hole Diameter D Max (Metric)	7.0
Disc Diameter (Metric)	16.0
Disc Diameter (Imperial)	0.63

Material Polyamide 6.6 heat stabilized (PA66HS)

Material Shortcut PA66HS

Flammability UL 94 HB

Operating Temperature	-40°F to +257°F (-40°C to +125°C)
------------------------------	-----------------------------------

ROHS Compliant	Yes
-----------------------	-----

Package Quantity (Imperial)	4000
------------------------------------	------

Package Quantity (Metric)	4000
----------------------------------	------

Customs Number	3926909988
-----------------------	------------

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[157-00287](#)