


Specification Sheet

Part Number: B-M20

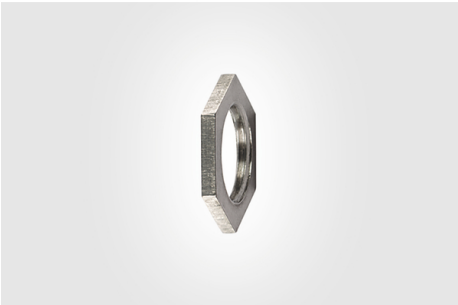

Nickel plated brass thread ensures secure connection with brass plated fittings.
Metric thread pattern works with metric thread fittings.

HelaGuard Metal Locknuts, Metric Thread, 20mm, Nickel Plated Brass, Silver, 10/pkg

Article Number	166-50171
Type	ALNPB-M20
Color	Metal (ML)
Quantity Per	bag
Product Description	Locknuts work with metric threaded fittings or knockout entries.
Short Description	HelaGuard Metal Locknuts, Metric Thread, 20mm, Nickel Plated Brass, Silver, 10/pkg
Global Part Name	ALNPB-M20-NPB-ML

Variant	Locknut
Thickness T (Imperial)	0.14
Thickness T (Metric)	3.5
Nominal Diameter (Imperial)	0.5
Nominal Diameter (Metric)	21
Material	Nickel Plated Brass (NPB)
Material Shortcut	NPB
Halogen Free	Yes
Operating Temperature	-58°F to +275°F (-50°C to +135°C)
ROHS Compliant	Yes
Package Quantity (Imperial)	10
Package Quantity (Metric)	10

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[B-M20](#)