

Specification Sheet

Part Number: 166-90250

Spiral reinforced construction provides protection from crushing yet remains extremely flexible.


Lightweight, easy-to-use material reduces installation time and labor costs.

Material stands up to vibration and limited torsional movement without creation of stress points or cracks.

Smooth inside bore protects wires and eases insertion of wire bundles.

UV resistant; suitable for use in outdoor applications.

Outer surface wipes clean in wash-down environments.

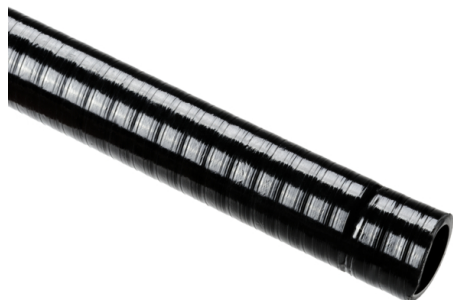

HelaGuard SR PVC Tubing, Smooth Bore, Smooth Cover, Std Wt, 1.00" Dia, Bk, 100 ft/Std. Reel

Article Number 166-90250

Type LPC1000

Color Black (BK)

Quantity Per reel

Product Description A lightweight, smooth tubing made of a spiral reinforced PVC material that provides high flexibility; well-suited for protecting wire and cable bundles in extremely tight spaces. UV resistant. Use with HelaGuard Metallic or Non Metallic Compression (PSR) Fittings for IP67 rating.

Short Description	HelGuard SR PVC Tubing, Smooth Bore, Smooth Cover, Std Wt, 1.00" Dia, Bk, 100 ft/Std. Reel
Global Part Name	LPC1000-PVC-BK
Length L (Imperial)	100.0
Length L (Metric)	30.5
Inner Diameter D (Imperial)	1.04
Inner Diameter D (Metric)	26.5
Outside Diameter OD (Imperial)	1.30
Outside Diameter OD (Metric)	33.1
Nominal Diameter (Imperial)	1
Nominal Diameter (Metric)	32
Material	Polyvinylchloride (PVC)
Material Shortcut	PVC
Flammability	EN IEC 61386-1
Halogen Free	No

UV Resistant (Yes/No)	No
Operating Temperature	+23°F to +158°F (-5°C to +70°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	100
Package Quantity (Metric)	30.48
Customs Number	3926909988

About HellermannTyton

HellermannTyton is a global manufacturer of cable management and identification solutions for automotive, solar, electrical, construction, industrial automation, broadband and other OEM markets. The company's integrated approach to product design, sustainability, production, quality assurance and delivery is optimized to benefit local and global customers. HellermannTyton operates in 40 countries, with North American headquarters in Milwaukee, Wisconsin. (www.hellermann.tyton.com).

© 2024 HellermannTyton. All Rights Reserved.

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Disclaimer](#)

[Terms and Conditions](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[166-90250](#)