


Specification Sheet

Part Number: 166-90449

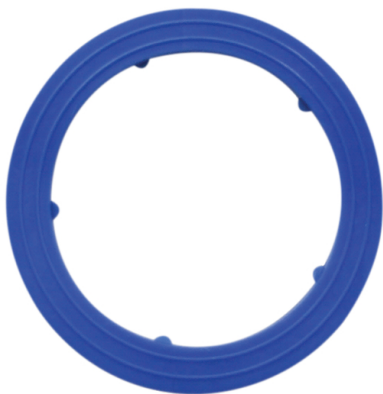

Polyester elastomer washer provides ingress protection against moisture and is oil resistant.

Small "pips" in bore retain washer onto metric threaded fittings.

Ribs on both sides of washer enhances sealing performance.

HelaGuard Accessories, Sealing Washer, M32-1", Polyester Elastomer, Blue, 10/pkg

Article Number	166-90449
----------------	-----------

Type	RSW100
------	--------

Color	Blue (BU)
-------	-----------

Quantity Per	pack
--------------	------

Product Description	Face sealing washer affixed between metric threaded fitting and entry wall surface to achieve IP66, IP67, IP68 and IP69 levels of ingress protection. Hardness 33 Shore D. Self-extinguishing and halogen free.
---------------------	---

Short Description	HelaGuard Accessories, Sealing Washer, M32-1", Polyester Elastomer, Blue, 10/pkg
-------------------	--

Global Part Name	RSW100-TPE-BU
------------------	---------------

Variant	Seal Washer
Thickness T (Imperial)	0.07
Thickness T (Metric)	1.8
Inner Diameter D (Imperial)	1.26
Inner Diameter D (Metric)	32.0
Outside Diameter OD (Imperial)	1.65
Outside Diameter OD (Metric)	42.0
Nominal Diameter (Imperial)	1
Nominal Diameter (Metric)	32.0
Material	Thermoplastic Elastomer (TPE)
Material Shortcut	TPE
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Operating Temperature	-58°F to +275°F (-50°C to +135°C)
Reach Compliant (Article 33)	No

Package Quantity (Imperial)	10
Package Quantity (Metric)	10
Customs Number	3926904500

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.
[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[166-90449](#)