


Specification Sheet

Part Number: 170-20800

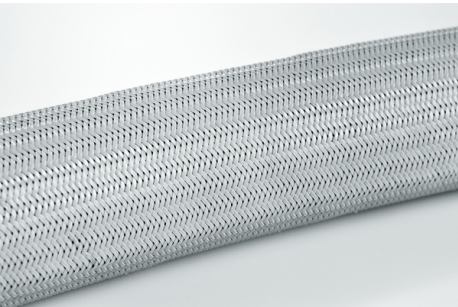

Nylon monofilament construction weave offers a tight braid that provides full coverage but will not rot or retain moisture.

Material performs well in wet applications and where abiding substrate has a smooth surface.

Helagaine Braided Sleeve, 8 mm Dia, PA66, GY, 328ft/Reel

Article Number	170-20800
Type	HEGPA6608
Color	Gray (GY)
Quantity Per	pack
Product Description	Helagaine Nylon Polyamide Expandable Braided Sleeve is a pliable yet durable sleeve that protects against cuts, abrasion and excessive wear caused by repetitive motion.
Short Description	Helagaine Braided Sleeve, 8 mm Dia, PA66, GY, 328ft/Reel
Global Part Name	HEGPA6608-PA66-GY

Length L (Imperial)	328.0
Length L (Metric)	100.0
Bundle Diameter Min (Imperial)	0.2
Bundle Diameter Min (Metric)	5
Bundle Diameter Max (Imperial)	0.39
Bundle Diameter Max (Metric)	10
Diameter D (Imperial)	0.31
Diameter D (Metric)	7.9
Nominal Diameter (Imperial)	0.31
Nominal Diameter (Metric)	8
Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66
Flammability	UL 94 V-2 FMVSS 302
Halogen Free	Yes
UV Resistant (Yes/No)	No

Use Conditions	For Indoor Use Only
Operating Temperature	-76°F to +302°F (-60°C to +150°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	328
Package Quantity (Metric)	100
Customs Number	5808100000

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.
[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[170-20800](#)