


Specification Sheet

Part Number: 181-22024

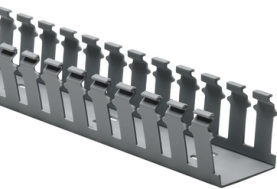

Strong fingers prevent unwanted breaking.  
Restricted opening prevents unintended removal of wires and permits any individual wire to be traced without disconnection.  
Supplied with mounting holes to streamline installation.  
Optional covers enhance protection and appearance.

|                     |                                                                                                                                                                                                                                                                                                                                                       |
|---------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
|                     |                                                                                                                                                                                                                                                                                                                                                       |
| Article Number      | 181-22024                                                                                                                                                                                                                                                                                                                                             |
| Type                | SL2X2                                                                                                                                                                                                                                                                                                                                                 |
| Color               | Gray (GY)                                                                                                                                                                                                                                                                                                                                             |
| Quantity Per        | carton                                                                                                                                                                                                                                                                                                                                                |
| Product Description | HellermannTyton Slotted Wall Wiring Duct features break-away fingers that provide additional access for wire leads. Each section of the duct is provided with two score lines. The upper score line is used to break away fingers when a greater opening is required. The lower score line allows the sidewall to be smoothly cut for joints and T's. |
| Short Description   | Slotted Wall Wiring Duct, 2" x 2", Non-Adhesive, PVC, Gray, 120ft/Carton                                                                                                                                                                                                                                                                              |
| Global Part Name    | SL2X2-PVC-GY                                                                                                                                                                                                                                                                                                                                          |

|                                  |              |
|----------------------------------|--------------|
| Length L (Imperial)              | 6.0          |
| Length L (Metric)                | 1.83         |
| Fixation Method                  | Non-Adhesive |
| Width W (Imperial)               | 2.0          |
| Width W (Metric)                 | 50.8         |
| Height H (Imperial)              | 2.07         |
| Height H (Metric)                | 52.6         |
| Mounting Hole Centers (Imperial) | 4.0          |

|          |                                                 |
|----------|-------------------------------------------------|
| Material | Polyvinylchloride - rigid extrusion grade (PVC) |
|----------|-------------------------------------------------|

|                   |     |
|-------------------|-----|
| Material Shortcut | PVC |
|-------------------|-----|

|              |    |
|--------------|----|
| Halogen Free | No |
|--------------|----|

|                       |    |
|-----------------------|----|
| UV Resistant (Yes/No) | No |
|-----------------------|----|

|                       |                |
|-----------------------|----------------|
| Operating Temperature | +122°F (+50°C) |
|-----------------------|----------------|

|                              |    |
|------------------------------|----|
| Reach Compliant (Article 33) | No |
|------------------------------|----|

|                |     |
|----------------|-----|
| ROHS Compliant | Yes |
|----------------|-----|

|                             |                                                  |
|-----------------------------|--------------------------------------------------|
| Certification/Specification | EN 50085-2-3_1A CSA UL EN 50085-1:2005 + A1:2013 |
| UL Recognized (US)          | Yes                                              |
| Package Quantity (Imperial) | 120.0                                            |
| Package Quantity (Metric)   | 36.58                                            |
| Customs Number              | 3925900000                                       |

## About HellermannTyton

HellermannTyton is a global manufacturer of cable management and identification solutions for automotive, solar, electrical, construction, industrial automation, broadband and other OEM markets. The company's integrated approach to product design, sustainability, production, quality assurance and delivery is optimized to benefit local and global customers. HellermannTyton operates in 39 countries, with North American headquarters in Milwaukee, Wisconsin. ([www.hellermann.tyton.com](http://www.hellermann.tyton.com)).

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[181-22024](#)