


Specification Sheet

Part Number: 553-50040

Slide Slit and optional center slits for easy wire insertion.
Smooth surface for clean and legible printing.

Supplied on a ladder style carrier so that markers can be kitted after printing.

A 3:1 shrink ratio means fewer skews as each marker covers a wider range of wire diameters.

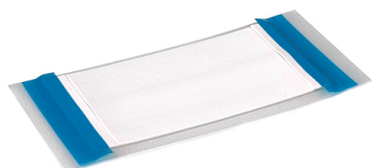

ShrinkTrak Labels, 1-Sided, 1-Slit, 1.0" (25.4mm), PO-X, White, 500/box

Article Number	553-50040
-----------------------	-----------

Type	HST24-8WH-S
-------------	-------------

Color	White (WH)
--------------	------------

Quantity Per	box
---------------------	-----

Product Description	HellermannTyton's ShrinkTrak heat shrinkable markers make it easy to mark wire, cable and other components. The military approved heat shrink tubing is flattened and assembled in a ladder style carrier system for easy printing using a thermal transfer printer. The ladder system creates a kit of markers that can be sorted, removed and applied in any order thus saving time, labor and speeding production.
----------------------------	---

Short Description	ShrinkTrak Labels, 1-Sided, 1-Slit, 1.0" (25.4mm), PO-X, White, 500/box
--------------------------	---

Global Part Name	HST24-8WH-S-PO-X-WH
-------------------------	---------------------

Variant	Thin-Wall
----------------	-----------

Width W (Imperial)	0.95
---------------------------	------

Width W (Metric)	24.13
-------------------------	-------

Thickness T (Imperial)	.003
-------------------------------	------

Thickness T (Metric)	.0762
-----------------------------	-------

Height H (Imperial)	1.69
----------------------------	------

Height H (Metric)	42.92
--------------------------	-------

Width of Liner (Metric)	76.2
--------------------------------	------

Width of Liner (Imperial)	3.0
----------------------------------	-----

Outside Diameter OD (Imperial)	1.0
---------------------------------------	-----

Outside Diameter OD (Metric)	25.4
-------------------------------------	------

Outside Diameter Max (Imperial)	1.0
--	-----

Outside Diameter Max (Metric)	25.4
--------------------------------------	------

Wall Thickness WT (Imperial)	0.039
-------------------------------------	-------

Wall Thickness WT (Metric)	0.99
-----------------------------------	------

Material	Polyolefin, cross-linked (PO-X)
Material Shortcut	PO-X
US MIL SPEC	SAE-AS81531 MIL-STD-202G Method 215K SAE-AMS-DTL-23053/5 Class 1 and 3
Flammability	UL 224 VW-1
Halogen Free	No
Operating Temperature	-67°F to +275°F (-55°C to +135°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Certification/Specification	UL 224 125 °C 600V VW-1
Package Quantity (Imperial)	500
Package Quantity (Metric)	500
Customs Number	3917320000
Labels per Column	1
Labels per Row	2

© 2022 HellermannTyton. All Rights Reserved.

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Disclaimer](#)

[Terms and Conditions](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[553-50040](#)