


Specification Sheet

Part Number: 553-50074

Slide Slit and optional center slits for easy wire insertion.
Smooth surface for clean and legible printing.

Supplied on a ladder style carrier so that markers can be kitted after printing.

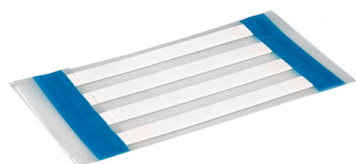

A 3:1 shrink ratio means fewer skews as each marker covers a wider range of wire diameters.

ShrinkTrak Labels, 1-Sided, 1-Slit, .125" (3.17mm), PO-X, White, 2000/box

Article Number	553-50074
-----------------------	-----------

Type	HST3-1WH-S
-------------	------------

Color	White (WH)
--------------	------------

Quantity Per	box
---------------------	-----

Product Description	HellermannTyton's ShrinkTrak heat shrinkable markers make it easy to mark wire, cable and other components. The military approved heat shrink tubing is flattened and assembled in a ladder style carrier system for easy printing using a thermal transfer printer. The ladder system creates a kit of markers that can be sorted, removed and applied in any order thus saving time, labor and speeding production.
----------------------------	---

Short Description	ShrinkTrak Labels, 1-Sided, 1-Slit, .125" (3.17mm), PO-X, White, 2000/box
--------------------------	---

Global Part Name	HST3-1WH-S-PO-X-WH
------------------	--------------------

Variant	Thin-Wall
---------	-----------

Width W (Imperial)	0.95
--------------------	------

Width W (Metric)	24.13
------------------	-------

Thickness T (Imperial)	.003
------------------------	------

Thickness T (Metric)	.0762
----------------------	-------

Height H (Imperial)	0.235
---------------------	-------

Height H (Metric)	5.69
-------------------	------

Width of Liner (Metric)	76.2
-------------------------	------

Width of Liner (Imperial)	3.0
---------------------------	-----

Outside Diameter OD (Imperial)	0.125
--------------------------------	-------

Outside Diameter OD (Metric)	3.2
------------------------------	-----

Outside Diameter Max (Imperial)	0.125
---------------------------------	-------

Outside Diameter Max (Metric)	3.2
-------------------------------	-----

Wall Thickness WT (Imperial)	0.031
------------------------------	-------

Wall Thickness WT (Metric)	0.79
----------------------------	------

Material	Polyolefin, cross-linked (PO-X)
Material Shortcut	PO-X
US MIL SPEC	MIL-STD-202G Method 215K SAE-AS81531 SAE-AMS-DTL-23053/5 Class 1 and 3
Flammability	UL 224 VW-1
Halogen Free	No
Operating Temperature	-67°F to +275°F (-55°C to +135°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Certification/Specification	CEN
Package Quantity (Imperial)	2000
Package Quantity (Metric)	2000
Customs Number	3917320000
Labels per Column	1
Labels per Row	2

© 2022 HellermannTyton. All Rights Reserved.

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Disclaimer](#)

[Terms and Conditions](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[553-50074](#)