


Specification Sheet

Part Number: 553-50078

Slide Slit and optional center slits for easy wire insertion.
Smooth surface for clean and legible printing.

Supplied on a ladder style carrier so that markers can be kitted after printing.

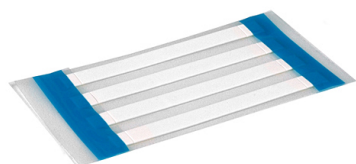

A 3:1 shrink ratio means fewer skews as each marker covers a wider range of wire diameters.

ShrinkTrak Labels, 1-Sided, Unslit, .125" (3.17mm), PO-X, White, 2500/box

Article Number	553-50078
-----------------------	-----------

Type	HST3-1WH
-------------	----------

Color	White (WH)
--------------	------------

Quantity Per	box
---------------------	-----

Product Description	HellermannTyton's ShrinkTrak heat shrinkable markers make it easy to mark wire, cable and other components. The military approved heat shrink tubing is flattened and assembled in a ladder style carrier system for easy printing using a thermal transfer printer. The ladder system creates a kit of markers that can be sorted, removed and applied in any order thus saving time, labor and speeding production.
----------------------------	---

Short Description	ShrinkTrak Labels, 1-Sided, Unslit, .125" (3.17mm), PO-X, White, 2500/box
--------------------------	---

Global Part Name	HST3-1WH-PO-X-WH
-------------------------	------------------

Variant	Thin-Wall
----------------	-----------

Width W (Imperial)	1.9
---------------------------	-----

Width W (Metric)	48.26
-------------------------	-------

Thickness T (Imperial)	.003
-------------------------------	------

Thickness T (Metric)	.0762
-----------------------------	-------

Height H (Imperial)	0.235
----------------------------	-------

Height H (Metric)	5.69
--------------------------	------

Width of Liner (Metric)	76.2
--------------------------------	------

Width of Liner (Imperial)	3.0
----------------------------------	-----

Outside Diameter OD (Imperial)	0.125
---------------------------------------	-------

Outside Diameter OD (Metric)	3.2
-------------------------------------	-----

Outside Diameter Max (Imperial)	0.125
--	-------

Outside Diameter Max (Metric)	3.2
--------------------------------------	-----

Wall Thickness WT (Imperial)	0.031
-------------------------------------	-------

Wall Thickness WT (Metric)	0.79
-----------------------------------	------

Material	Polyolefin, cross-linked (PO-X)
Material Shortcut	PO-X
US MIL SPEC	SAE-AS81531 SAE-AMS-DTL-23053/5 Class 1 and 3 MIL-STD-202G Method 215K
Flammability	UL 224 VW-1
Halogen Free	No
Operating Temperature	-67°F to +275°F (-55°C to +135°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Certification/Specification	CEN
Package Quantity (Imperial)	2500
Package Quantity (Metric)	2500
Customs Number	3917320000
Labels per Column	1
Labels per Row	1

© 2022 HellermannTyton. All Rights Reserved.

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Disclaimer](#)

[Terms and Conditions](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[553-50078](#)