


Specification Sheet

Part Number: 556-00165

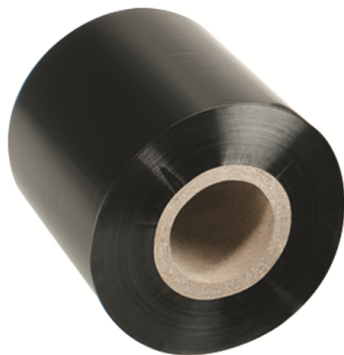

Ribbons are resin based for the best print durability

Ribbons are available to fit all HellermannTyton printers for easy resupply

Ribbons are available in colors for maximizing design printing capabilities

Ribbons meet UL recognition and Military standard where applicable to meet specific industry label requirements

Thermal Transfer Ribbon, SwiftMark, 2.0" x 984', 1" Core, 100 Resin, Black, 1/pkg

Article Number	556-00165
-----------------------	-----------

Type	SM100OUT
-------------	----------

Color	Black (BK)
--------------	------------

Quantity Per	EA
---------------------	----

Product Description	HellermannTyton thermal transfer ribbons are designed for use in HellermannTyton thermal transfer printers. Available on 1/2" and 1" cores, the ribbons are coated side out and available in two different lengths. All ribbons are available in a variety of colors and are matched to the HellermannTyton label stock to give the best chemical and abrasion resistance.
----------------------------	--

Short Description	Thermal Transfer Ribbon, SwiftMark, 2.0" x 984', 1" Core, 100 Resin, Black, 1/pkg
--------------------------	---

Global Part Name	SM100OUT-PET-BK
Length L (Imperial)	984.0
Length L (Metric)	300.0
Reel Diameter (Imperial)	2.5
Reel Diameter (Metric))	63.5
Reel Width (Imperial)	2.0
Reel Width (Metric)	50.8
Variant	Colored ribbon
Width W (Imperial)	2.0
Width W (Metric)	50.8
Material	Polyester (PET)
Material Shortcut	PET
Operating Temperature	+40°F to +300°F (+4°C to +82°C)
Reach Compliant (Article 33)	Yes

ROHS Compliant	Yes
-----------------------	-----

Package Quantity (Imperial)	1
------------------------------------	---

Package Quantity (Metric)	1
----------------------------------	---

Customs Number	3702390100
-----------------------	------------

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[556-00165](#)