


Specification Sheet

Part Number: 596-00190

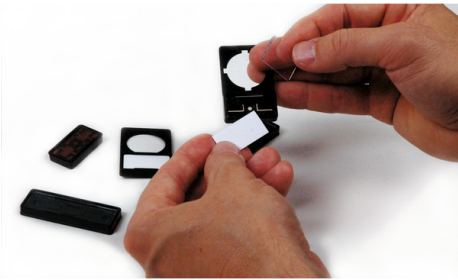

The legend bases can be fixed to flat surfaces by a rivet, cable ties, screws and also come with an adhesive backing for easy installation. Used with the legend inserts and clear covers, the bases provide durable and permanent identification.

Plastic button base, without locators, 1.12" x 1.87", Plastic, Black, 100/pkg

Article Number	596-00190
Type	PTOA-22
Color	Black (BK)
Quantity Per	pack
Product Description	Plastic Nameplate labels are less costly than plastic or metal engraved plates, saving material costs. Plastic Nameplate labels are made of a UL94VO rated polycarbonate that can be mounted mechanically or using an adhesive backing. HellermannTyton thermal transfer or laser labels can be printed and applied to the inserts and covered with a clear plastic cover to protect printed text.
Short Description	Plastic button base, without locators, 1.12" x 1.87", Plastic, Black, 100/pkg

Global Part Name	PTOA-22-PC-BK
Width W (Imperial)	1.12
Width W (Metric)	28
Height H (Imperial)	1.87
Height H (Metric)	47
Mounting Hole Diameter D (Imperial)	0.88
Mounting Hole Diameter D (Metric)	22.35 mm
Material	Polycarbonate (PC)
Material Shortcut	PC
Adhesive	Acrylic
Flammability	UL 94 V-0
Halogen Free	No
Adhesive Operating Temperature	-22°F to +266°F (-30°C to +130°C)
Operating Temperature	-22°F to +266°F (-30°C to +130°C)

Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	100
Package Quantity (Metric)	100
Customs Number	3919905060

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[596-00190](#)