

Specification Sheet


Part Number: 596-00881

Made with UV-stable inks and materials for durability and weather resistance.

Polyester is resistant to chemicals and solvents and will remain legible in dirty environments.

High abrasion and scuff resistance for high-performance labeling.

Meets NEC & IFC standards for printed text, character height, color and outdoor UV stability to pass inspections.

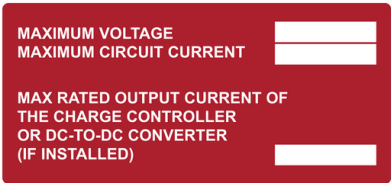

Solar Label, Printable, Maximum Voltage, 3.75" x 2.12", PET, Red, 10/pkg

Article Number	596-00881
Type	DC201710
Color	Red (RD)
Quantity Per	pack

Product Description	HellermannTyton makes it easier than ever for solar installers to meet PV labeling codes. Solar Label Convenience Packs allow installers to quickly and economically purchase high quality preprinted NEC 2014 and 2017 code-compliant solar installation labels. Packaged in 10-count quantities to meet the needs of smaller scale solar installations and independent contractors, Solar Label Convenience Packs are available in HellermannTyton's most popular preprinted NEC 2014 and 2017 code-compliant solar label formats. Each Solar Label Convenience Pack contains 10 solar installation labels. Choose from a variety of regular and reflective preprinted labels. For enhanced durability, clear laminate overlay labels are also available in a convenience pack.
Short Description	Solar Label, Printable, Maximum Voltage, 3.75" x 2.12", PET, Red, 10/pkg
Global Part Name	DC201710-840/281-RD
Technical Description	Printable Solar Label-2017 Code, Maximum Voltage Label, 3.75" X 2.12", Polyester, Red, 10/pkg
Width W (Imperial)	3.75
Width W (Metric)	95.25
Thickness T (Imperial)	0.0025
Thickness T (Metric)	64.0
Height H (Imperial)	2.12
Height H (Metric)	53.80
Width of Liner (Metric)	98.29

Width of Liner (Imperial)	3.87
Material	Type 840/281, Polyester, UV-stabilized, clear polyester laminate (840/281)
Material Shortcut	840/281
Adhesive	Acrylic
Halogen Free	Yes
Adhesive Operating Temperature	-40°F to +302°F (-40°C to +150°C)
Operating Temperature	-40°F to +302°F (-40°C to +150°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Certification/Specification	UL 969 NEC2017 CSA 66956
Warranty (US)	Yes
UL Recognized (US)	Yes
Package Quantity (Imperial)	10
Package Quantity (Metric)	10

Customs Number	3919102055
-----------------------	------------

Labels per Column	1
--------------------------	---

Labels per Row	1
-----------------------	---

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[596-00881](#)