

Specification Sheet


Part Number: 596-00891

Made with UV-stable inks and materials for durability and weather resistance.

Polyester is resistant to chemicals and solvents and will remain legible in dirty environments.

High abrasion and scuff resistance for high-performance labeling.

Meets NEC & IFC standards for printed text, character height, color and outdoor UV stability to pass inspections.

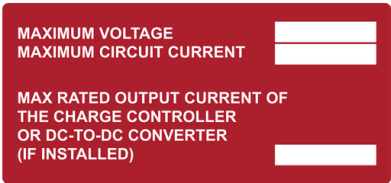

Solar Label, Printable, Maximum Voltage, 3.75" x 2.12", PET, Red, 50/roll

Article Number	596-00891
Type	DC2017
Color	Red (RD)
Quantity Per	roll
Product Description	Designed with cross-laminated UV stable materials, these variable print solar installation labels are designed to accept printing from any standard thermal transfer printer using a resin-based ink ribbon for the best durability. Print your voltage information directly on the label and then laminate with an optional clear acrylic laminate material for added protection. These labels can be used to print disconnecting means and breaker series directly on the labels for a more professional result and a smoother inspection process.

Short Description	Solar Label, Printable, Maximum Voltage, 3.75" x 2.12", PET, Red, 50/roll
Global Part Name	DC2017-840/281-RD
Technical Description	Solar Label, Printable, Maximum Voltage, 3.75" x 2.12", PET, Red, 50/roll
Width W (Imperial)	3.75
Width W (Metric)	95.25
Thickness T (Imperial)	0.0025
Thickness T (Metric)	64.0
Height H (Imperial)	2.12
Height H (Metric)	53.8
Width of Liner (Metric)	98.29
Width of Liner (Imperial)	3.87
Material	Type 840/281, Polyester, UV-stabilized, clear polyester laminate (840/281)
Material Shortcut	840/281

Adhesive	Acrylic
Halogen Free	Yes
Adhesive Operating Temperature	-40°F to +302°F (-40°C to +150°C)
Operating Temperature	-40°F to +302°F (-40°C to +150°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Certification/Specification	CSA 66956 UL 969 NEC2017 IFC 2012
Warranty (US)	Yes
UL Recognized (US)	Yes
Package Quantity (Imperial)	50
Package Quantity (Metric)	50
Customs Number	3919102055
Labels per Column	1
Labels per Row	1

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Disclaimer](#)

[Terms and Conditions](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[596-00891](#)