


Nextracker Torque Tube Hanger

Features and Benefits

- One-piece ratchet clamp can be pre installed, conveniently adding wires at installation or a later time.
- A quick, toolless, one-handed installation. Releasable function to allow for adjusting or adding wire.
- Clamp saddle provides additional routing option using a cable tie, eliminating the need to drill or add complex routing parts.
- Impact modified, heat and UV stabilized PA66 provides long-term durability in hazardous solar conditions.
- Nextracker-specific stainless steel mounting hanger designed for severe conditions of single axis tracker movement.



Material	Polyamide 6.6 high impact modified, heat and UV stabilized (PA66HIRHSUV), Stainless Steel (SS304)
Color	Black (BK)
Operating Temperature	-40°F to +221°F (-40°C to +105°C)

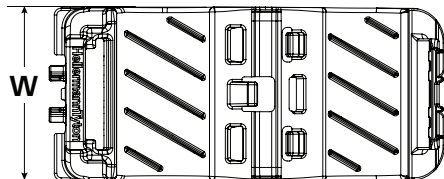

PART NO.	TYPE	Min. Bundle Diameter in. (mm)	Max. Bundle Diameter in. (mm)	Fixation Method	Width (W) in. (mm)	Pkg. Qty.
156-04193	IRCCNEXTT	0.8 (19.3)	1.4 (36.1)	Mounting Hanger	1.4 (34.8)	200

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Contact HellermannTyton for more information.

Visit www.hellermann.tyton.com or call 800.537.1512

Disclaimer: The information in this datasheet is for informational purposes only. Information is subject to change at any time without notice.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[156-04193](#)