

F-Series

SINGLE POLE TOGGLE SWITCHES

General purpose workhorses with options tailored to meet most any need. Ratings to 20A 277VAC, various actuator, bushing, termination, and circuit choices allow this versatile switch to easily integrate into a variety of different applications. The F-Series is appropriate for usage in low voltage DC applications.



Resources:

Download 3D CAD Files

[IGS >](#) [STP >](#)

Product Highlights:

- Ratings to 20A
- Suitable for low voltage 12/24V DC
- Variety of termination options
- Consult factory for large choice of bushing/toggle length combinations

Typical Applications:

- Marine
- Food Service
- Generator
- Industrial Control
- Office Automation



Carling Technologies®
Innovative Designs. Powerful Solutions.

Carling Technologies, Inc.
60 Johnson Avenue, Plainville, CT 06062
Email: sales@carlingtech.com
Application Support: team2@carlingtech.com
Phone: 860.793.9281 Fax: 860.793.9231

www.carlingtech.com

Dielectric Strength

1000V - live to dead metal parts

Electrical Life

50,000 cycles - maintained
25,000 cycles - momentary

Operating Temperature

0°F to 150°F (-17.8°C to +65.6°C)

2FA54 - 73 / TABS

¹
Base Part Number

²
Actuator
Style

³
Tab Terminals

1 BASE PART NUMBER: SERIES / CIRCUITRY / RATING / TERMINATION¹

10A 250VAC; 15A 125VAC; 3/4 HP 125-250VAC

	Solder Lug	.250 Tab QC	Screw Terminals
On-None-Off	2FA53	2FA53-.../TABS	2FA54
(On)-None-Off	6FA53	6FA53-.../TABS	6FA54
On-None-(Off)	6FA57	6FA57-.../TABS	6FA58
On-None-On	2FB53	2FB53-.../TABS	2FB54
On-None-(On)	6FB53	6FB53-.../TABS	6FB54
On-Off-On	2FC53	2FC53-.../TABS	2FC54
On-Off-(On)	6FC53	6FC53-.../TABS	6FC54

Additional ratings up to 20A 125VAC, 12A 250VAC, 1HP 120-240 VAC available. Consult factory for specifics.

2 ACTUATOR STYLE BAT STYLE TOGGLE²


unsealed	sealed	toggle length	bushing length
73	78	0.687	0.465
E3	E8	2.000	0.465

3 TAB TERMINALS

/TABS Tab Terminals
(blank) Leave blank if tab terminals not required.

Notes:

- Consult factory for .187 tab, wire lead and combination screw/tab/solder lug termination callouts.
- Additional toggle options are available. Consult factory.
- () indicates momentary function.

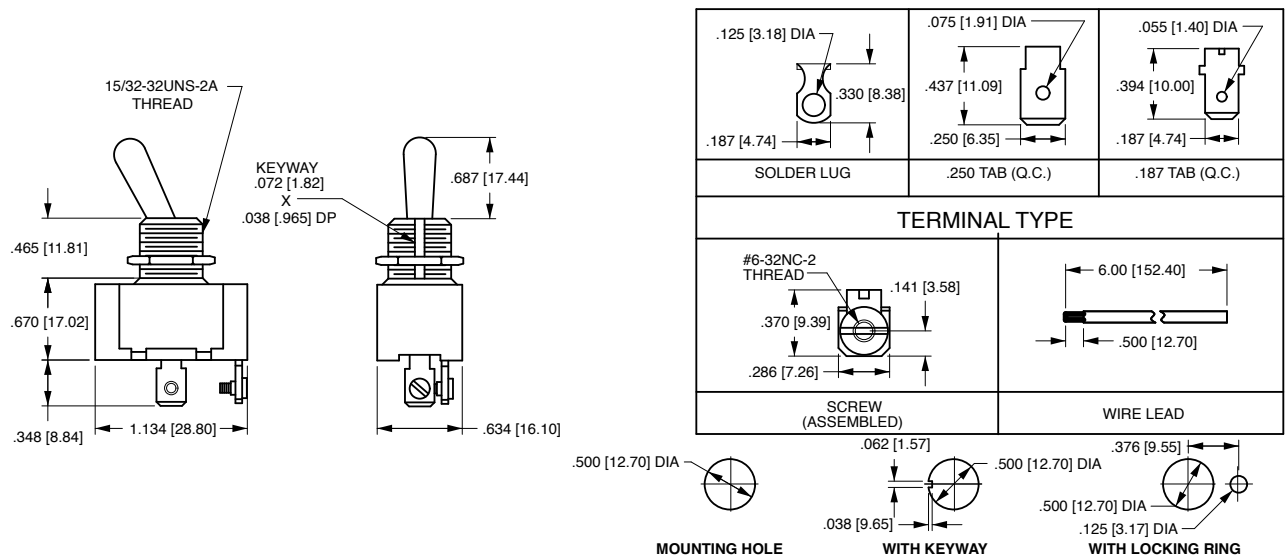

*Manufacturer reserves the right to change product specification without prior notice.

Authorized Sales Representatives and Distributors

Click on a region of the map below to find your local representatives and distributors or visit www.carlingtech.com/findarep.



About Carling

Founded in 1920, Carling Technologies is a leading manufacturer of electrical and electronic switches and assemblies, circuit breakers, electronic controls, power distribution units, and multiplexed power distribution systems. With four ISO9001 and IATF16949 registered manufacturing facilities and technical sales offices worldwide, Carling Technologies Sales, Service and Engineering teams do much more than manufacture electrical components, they engineer powerful solutions! To learn more about Carling please visit www.carlingtech.com/company-profile.

To view all of Carling's environmental, quality, health & safety certifications please visit www.carlingtech.com/environmental-certifications

Worldwide Headquarters

Carling Technologies, Inc.
60 Johnson Avenue, Plainville, CT 06062
Phone: 860.793.9281 **Fax:** 860.793.9231
Email: sales@carlingtech.com

Northern Region Sales Office: nrsm@carlingtech.com
Southeast Region Sales Office: sersm@carlingtech.com
Midwest Region Sales Office: mrsm@carlingtech.com
West Region Sales Office: wrsm@carlingtech.com
Latin America Sales Office: larsm@carlingtech.com

Asia-Pacific Headquarters

Carling Technologies, Asia-Pacific Ltd.,
Suite 1607, 16/F Tower 2, The Gateway,
Harbour City, 25 Canton Road,
Tsimshatsui, Kowloon, Hong Kong
Phone: Int + 852-2737-2277 **Fax:** Int + 852-2736-9332
Email: sales@carlingtech.com.hk

Shenzhen, China: shenzhen@carlingtech.com
Shanghai, China: shanghai@carlingtech.com
Pune, India: india@carlingtech.com
Kaohsiung, Taiwan: taiwan@carlingtech.com
Yokohama, Japan: japan@carlingtech.com

Europe | Middle East | Africa Headquarters

Carling Technologies LTD
4 Airport Business Park, Exeter Airport,
Clyst Honiton, Exeter, Devon, EX5 2UL, UK
Phone: Int + 44 1392.364422 **Fax:** Int + 44 1392.364477
Email: ltd.sales@carlingtech.com

Germany: gmbh@carlingtech.com
France: sas@carlingtech.com



Carling Technologies®

Innovative Designs. Powerful Solutions.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Carling Technologies:

[2FA54-73](#) [2FC53-78](#) [2FA54-63](#) [2FA53-73](#) [2FC54-73](#) [6FC54-73](#) [6FC63-A2/TABS](#) [2FB53-73/TABS](#) [2FC53-78/TABS](#) [2FA53-73/TABS](#) [2FC53-73/TABS](#) [6FC63-A7/TABS](#) [2FB54-73](#) [2FA51-73](#) [2FA53-78/TABS](#) [2FB53-73](#) [2FB63-22](#) [2FC53-73](#) [6FA54-73](#) [6FB54-78](#) [6FC53-73/TABS](#) [6FC58-73](#) [6FC64-73](#) [2FA54-E3](#) [6FA53-73](#) [6FC53-78](#) [6FC51-73](#) [2FB51-73](#) [2FC64-73](#) [2FC63-52](#) [2FC63-63/TABS](#) [2FC63-57](#) [2FC54-E3](#) [2FC51-73](#) [2FB53-A2](#) [2FB53-A7/TABS](#) [2FB53-22](#) [2FB53-52](#) [2FB53-78](#) [2FB63-63/TABS](#) [2FA64-73](#) [2FA63-73/TABS](#) [2FA51-63](#) [2FA53-52/TABS](#) [2FA53-63/TABS](#) [2FA53-68/TABS](#) [2FC63-A2](#) [2FC63-78/TABS](#) [2FC63-52/TABS](#) [2FC54-22](#) [2FC54-63](#) [2FC63-73/TABS](#) [2FC53-63/TABS](#) [2FC53-68/TABS](#) [2FC63-68](#) [2FB54-63](#) [2FB63-E3](#) [2FC53-A7/TABS](#) [2FC64-78](#) [2FC53-E3/TABS](#) [2FB63-73](#) [2FC53-A2](#) [2FC53-E3](#) [2FC63-63](#) [2FB54-E3](#) [2FB63-63](#) [2FB63-68](#) [2FC53-52](#) [2FC53-63](#) [2FB53-63](#) [2FC63-73](#) [2FC63-78](#) [2FB64-63](#) [2FC54-A7](#) [2FB53-78/TABS](#) [2FB63-52](#) [2FC51-78](#) [2FB63-73/TABS](#) [2FB64-78](#) [2FC54-78](#) [2FC53-A2/TABS](#) [2FA63-78/TABS](#) [2FA63-A2/TABS](#) [2FB64-73](#) [2FB63-68/TABS](#) [2FA54-57](#) [2FA64-63](#) [2FB54-78](#) [2FB53-63/TABS](#) [2FB63-78](#) [2FB54-22](#) [2FA64-78](#) [2FB51-78](#) [2FA53-E3/TABS](#) [2FA63-78](#) [2FA53-78](#) [2FA61-73](#) [2FA54-E8](#) [2FA54-A7](#) [2FA63-A2](#)