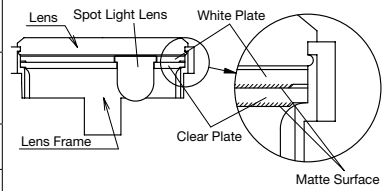


 
 
 
SLC30/40 series Combination Display Lights Accessories

Accessories / Replacement Parts

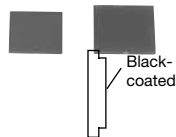
Accessories

Name & Shape	Applicable Model	Part No.	Ordering No.	Package Quantity	Remarks
Spot Illumination Kit for Type F Window  (supplied with the spot illumination type SLC)	SLC30N	SLCN-3ST-F2	SLCN-3ST-F2	1	
	SLC40N	SLCN-4ST-F2	SLCN-4ST-F2	1	
White Screen for Spot Illumination	SLC30N	SLDN-3C-FW-ST1	SLDN-3C-FW-ST1	1	
	SLC40N	SLDN-4PF-FW-ST1	SLDN-4PF-FW-ST1	1	

Tool Accessories

Name & Shape	Material	Part No.	Ordering No.	Package Quantity	Remarks
Lamp Holder Tool 	Rubber	OR-44	OR-44	1	Used for replacing LED lamps (LFTD) for SLC30 Type C (Split-window).
Lamp Holder Tool 	Rubber	OR-55	OR-55	1	Used for replacing LED lamps (LSTD). 
LED Unit Removal Tool 	Metal	MT-101	MT-101	1	Used for removing the LED unit for the SLC30/40 series.
Lens Unit Removal Tool 	Rubber (Ring: metal)	MT-S01	MT-S01	1	Used for removing the lens unit.

Marking Plate, Color Screens

Name & Shape	Series	Applicable Window	Dimensions (mm)	Part No.	Ordering No.	Color Code	Package Quantity
Color Screen 	SLC30	F	27H × 27W × 1.0t	SLDN-3C-*	SLDN-3C-*	A: Amber C: Clear (clear screen) FW: White (white screen) G: Green R: Red (Type F) RL: Red (Except Type F) S: Blue Y: Yellow	5
		H and V	27H × 57W × 1.0t	SLC-3PH-*	SLC-3PH-*		
		H (split-window)	27H × 28.5W × 1.0t	SLC-3PH2-*	SLC-3PH2-*		
		L	27H × 87W × 1.0t	SLC-3PL-*	SLC-3PL-*		
		G	57H × 57W × 1.0t	SLC-3PG-*	SLC-3PG-*		
		C	12H × 27W × 1.0t	SLC-3PC-*	SLC-3PC-*		
	SLC40	F	35.8H × 35.8W × 1.0t	SLCN-4PF-*	SLCN-4PF-*		
		H and V	75.8H × 35.8W × 1.0t	SLC-4PH-*	SLC-4PH-*		
		L	35.8H × 115.8W × 1.0t	SLC-4PL-*	SLC-4PL-*		
		G	75.8H × 75.8W × 1.0t	SLC-4PG-*	SLC-4PG-*		
		C	15.8H × 35.8W × 1.0t	SLC-4PC-*	SLC-4PC-*		
Black Marking Plate 	SLC30	F	27H × 27W × 1.0t	SLDN-3C-FWM	SLDN-3C-FWM	—	1
		H and V	27H × 57W × 1.0t	SLC-3PH-FWM	SLC-3PH-FWM		
		H (split-window)	27H × 28.5W × 1.0t	SLC-3PH2-FWM	SLC-3PH2-FWM		
		L	27H × 87W × 1.0t	SLC-3PL-FWM	SLC-3PL-FWM		
		G	57H × 57W × 1.0t	SLC-3PG-FWM	SLC-3PG-FWM		
		C	12H × 27W × 1.0t	SLC-3PC-FWM	SLC-3PC-FWM		
	SLC40	F	35.8H × 35.8W × 1.0t	SLCN-4PF-FWM	SLCN-4PF-FWM		
		H and V	75.8H × 35.8W × 1.0t	SLC-4PH-FWM	SLC-4PH-FWM		
		L	35.8H × 115.8W × 1.0t	SLC-4PL-FWM	SLC-4PL-FWM		
		G	75.8H × 75.8W × 1.0t	SLC-4PG-FWM	SLC-4PG-FWM		
		C	15.8H × 35.8W × 1.0t	SLC-4PC-FWM	SLC-4PC-FWM		

Note: For insertion order into SLC frames or markings, see operating instructions on page 31 and 32.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

IDEC:

[SLCN-2ET-G](#) [SLCN-4PF-S](#) [SLCN-2ET-S](#) [SLCN-2ET-A](#) [SLCN-2ET-W](#) [SLCN-4PF-G](#) [SLCN-42M-Y](#) [SLCN-1ET-G](#)
[SLCN-42MW-RG](#) [SLCN-1ET-W](#) [SLCN-1ET-R](#) [SLCN-4PF-Y](#) [SLCN-JP34](#) [SLCN-42M-R](#) [SLCN-42M-W](#) [SLCN-2ET-Y](#)
[SLCN-2ET-R](#) [SLCN-42M-A](#) [SLCN-2ETW-RG](#) [SLCN-42M-G](#) [SLCN-4PF-A](#) [SLCN-4PF-R](#) [SLCN-4PF-FW](#) [SLCN-](#)
[1ET-A](#) [SLCN-JP35](#) [SLCN-JP44PN10](#) [SLCN-42M-S](#) [SLCN-JP45PN10](#) [SLCN-4PF-C](#) [SLCN-2ET-PW](#) [SLCN-42M-PW](#)
[SLCN-4PF-FWM](#) [SLCN-1ET-Y](#) [SLC-6EP-W](#) [SLC-6EP-Y](#) [SLC-6SP-R](#) [SLC-6SP-W](#) [SLC-6SP-Y](#) [SLC-JP30](#) [SLC-1B](#)
[SLC-1DP](#) [SLC-1EH-A](#) [SLC-1EH-G](#) [SLC-1EH-R](#) [SLC-1EH-Y](#) [SLC-1EP-Y](#) [SLC-1SHN-A](#) [SLC-1SHN-G](#) [SLC-1SHN-](#)
[R](#) [SLC-1SHN-W](#) [SLC-1SHN-Y](#) [SLC-1SP-A](#) [SLC-2EH-A](#) [SLC-2EH-G](#) [SLC-2EH-W](#) [SLC-3A19-B](#) [SLC-3A1-B](#) [SLC-](#)
[3A1-K](#) [SLC-3A20-B](#) [SLC-3A21-B](#) [SLC-3A22-B](#) [SLC-3A23-B](#) [SLC-3A24-B](#) [SLC-3A25-B](#) [SLC-3A26-B](#) [SLC-3A27-B](#)
[SLC-3A39-K](#) [SLC-3A3-B](#) [SLC-3A40-B](#) [SLC-3A40-K](#) [SLC-3A4-B](#) [SLC-3A4-K](#) [SLC-3A5-B](#) [SLC-3A5-K](#) [SLC-3A6-B](#)
[SLC-3F2](#) [SLC-3F20](#) [SLC-3F21](#) [SLC-3F22](#) [SLC-3F23](#) [SLC-3F24](#) [SLC-3F25](#) [SLC-3F26](#) [SLC-3F27](#) [SLC-3F28](#) [SLC-](#)
[3F29](#) [SLC-3F3](#) [SLC-3F30](#) [SLC-3F31](#) [SLC-3F32](#) [SLC-3F33](#) [SLC-3F34](#) [SLC-1EP-A](#) [SLC-1EP-G](#) [SLC-1EP-R](#) [SLC-](#)
[1EP-W](#) [SLC-1SP-G](#) [SLC-1SP-R](#) [SLC-1SP-W](#) [SLC-1SP-Y](#)