




V3S


Type	• Switches
Product type	• Burgess Sealed Miniature Micro switch
Typical markets	• material handling • building automation & security • transportation • distribution
Typical applications	• forklifts • alarm devices • specialist vehicles • international catalog distributors
Dimensions	• 32 x 24 x 10 mm
Characteristics	• sealed IP67 • flying leads • robust construction
Rating	• 250 VAC, 5 A
Actuators	• plunger • plain lever • roller lever
Approvals/Quality	• ENEC • UL • CSA



Dimensions

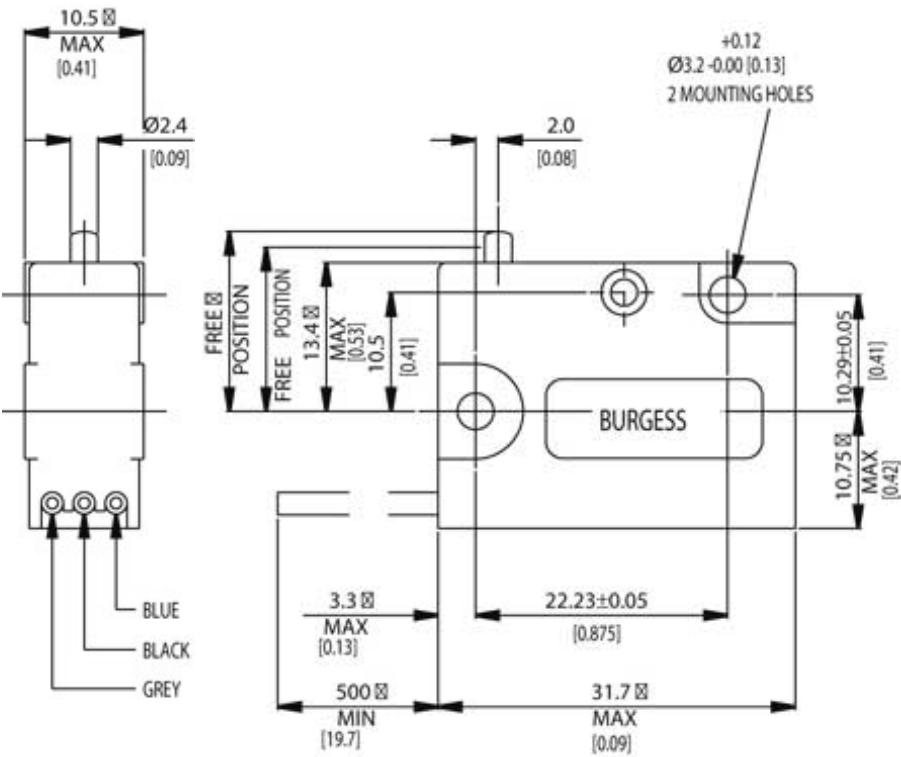

Circuits

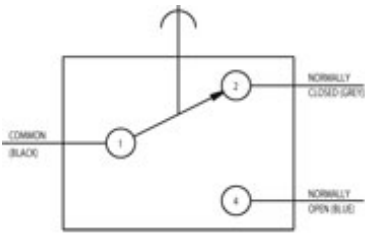

Performance

Preferred range

Partnumber	Terminal	Actuator	Electrical rating @	
			ENEC	UL/CSA
<u>V3SUL</u>	prewired	plunger	250 VAC 5	250 VAC 5
	0.5M		A	A
<u>V3SY1UL</u>	prewired	plain lever 26.2	250 VAC 5	250 VAC 5
	0.5M	mm	A	A
<u>V3SYRUL</u>	prewired	roller lever 11.7	250 VAC 5	250 VAC 5
	0.5M	mm	A	A

<u>V3SYR1UL</u>	rewired	roller lever 24.2	250 VAC 5	250 VAC 5
	0.5M	mm	A	A



V3SUL

Dimensions	32 mm
Dimensions	24 mm
Dimensions	10 mm
Terminal	prewired 0.5M
Circuit	CO
Protection	IP67
Actuator	plunger
Contacts	Ag
Electrical rating ENEC	250 VAC
Electrical rating UL/CSA	250 VAC
Actuating force	3.9 Nm
Release force	1.1 N
Free position (FP)	15.9 mm
Operating position (OP)	14.5 mm
Movement	0.4 mm
Overtravel	depress to case

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Johnson Electric:](#)

[V3SUL](#) [V3SYRUL](#) [V3SY1UL](#) [V3SYR1UL](#)