


Power Transistors

TO-3 Case

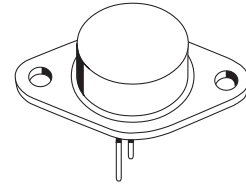

TYPE NO.		I _C	P _D	BV _{CEO}	BV _{CE0}	h _{FE}		@ I _C	V _{CE(SAT)}	@ I _C	f _T
NPN	PNP	(A) MAX	(W)	(V) MIN	(V) MIN	MIN	MAX	(A)	(V) MAX	(A)	(MHz) MIN
2N3055	MJ2955	15	115	100	60	5.0	--	10	3.0	10	2.5
2N3442		10	117	160	140	20	70	3.0	5.0	10	--
2N3713	2N3789	10	150	80	60	15	--	3.0	1.0	5.0	4.0
2N3714	2N3790	10	150	100	80	15	--	3.0	1.0	5.0	4.0
2N3715	2N3791	10	150	80	60	30	--	3.0	1.0	5.0	4.0
2N3716	2N3792	10	150	100	80	30	--	3.0	1.0	5.0	4.0
2N3771		30	150	50	40	15	60	15	2.0	15	--
2N3772		20	150	100	60	15	60	10	1.4	10	--
2N3773	2N6609	16	150	160	140	15	60	8.0	4.0	16	--
2N4913	2N4904	5.0	87.5	40	40	7.0	--	5.0	1.5	5.0	4.0
2N4914	2N4905	5.0	87.5	60	60	7.0	--	5.0	1.5	5.0	4.0
2N4915	2N4906	5.0	87.5	80	80	7.0	--	5.0	1.5	5.0	4.0
2N5067	2N4901	5.0	87.5	40	40	7.0	--	5.0	1.5	5.0	4.0
2N5068	2N4902	5.0	87.5	60	60	7.0	--	5.0	1.5	5.0	4.0
2N5069	2N4903	5.0	87.5	80	80	7.0	--	5.0	1.5	5.0	4.0
2N5301	2N4398	30	200	40	40	15	60	15	4.0	30	4.0
2N5302	2N4399	30	200	60	60	15	60	15	4.0	30	4.0
2N5303	2N5745	20	200	80	80	15	60	10	2.0	20	2.0
2N5629	2N6029	16	200	100	100	25	100	8.0	2.0	16	1.0
2N5632	2N6229	10	150	100	100	25	100	5.0	2.0	10	1.0
2N5877	2N5875	10	150	60	60	4.0	--	10	3.0	10	4.0
2N5878	2N5876	10	150	80	80	4.0	--	10	3.0	10	4.0
2N5881	2N5879	15	160	60	60	4.0	--	15	4.0	15	4.0
2N5882	2N5880	15	160	80	80	4.0	--	15	4.0	15	4.0
2N5885	2N5883	25	200	60	60	20	100	10	4.0	25	4.0
2N5886	2N5884	25	200	80	80	20	100	10	4.0	25	4.0
2N6055	2N6053	8.0	100	60	60	750	18,000	4.0	3.0	8.0	4.0
2N6056	2N6054	8.0	100	80	80	750	18,000	4.0	3.0	8.0	4.0
2N6057	2N6050	12	150	60	60	750	18,000	6.0	3.0	12	4.0
2N6058	2N6051	12	150	80	80	750	18,000	6.0	3.0	12	4.0
2N6059	2N6052	12	150	100	100	750	18,000	6.0	3.0	12	4.0
	2N6246	15	125	70	60	20	100	7.0	2.5	15	4.0
	2N6247	15	125	90	80	20	100	6.0	3.5	15	4.0

OUTSTANDING SUPPORT AND SUPERIOR SERVICES



PRODUCT SUPPORT

Central's operations team provides the highest level of support to insure product is delivered on-time.

- Supply management (Customer portals)
- Inventory bonding
- Consolidated shipping options
- Custom bar coding for shipments
- Custom product packing

DESIGNER SUPPORT/SERVICES

Central's applications engineering team is ready to discuss your design challenges. Just ask.

- Free quick ship samples (2nd day air)
- Online technical data and parametric search
- SPICE models
- Custom electrical curves
- Environmental regulation compliance
- Customer specific screening
- Up-screening capabilities
- Special wafer diffusions
- PbSn plating options
- Package details
- Application notes
- Application and design sample kits
- Custom product and package development

REQUESTING PRODUCT PLATING

1. If requesting Tin/Lead plated devices, add the suffix " TIN/LEAD" to the part number when ordering (example: 2N2222A TIN/LEAD).
2. If requesting Lead (Pb) Free plated devices, add the suffix " PBFREE" to the part number when ordering (example: 2N2222A PBFREE).

CONTACT US

Corporate Headquarters & Customer Support Team

Central Semiconductor Corp.
145 Adams Avenue
Hauppauge, NY 11788 USA
Main Tel: (631) 435-1110
Main Fax: (631) 435-1824
Support Team Fax: (631) 435-3388
www.centrasemi.com

Worldwide Field Representatives:
www.centrasemi.com/wwreps

Worldwide Distributors:
www.centrasemi.com/wwdistributors

For the latest version of Central Semiconductor's **LIMITATIONS AND DAMAGES DISCLAIMER**, which is part of Central's Standard Terms and Conditions of sale, visit: www.centrasemi.com/terms

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Central Semiconductor:](#)

[2N5629 PBFREE](#) [2N4398 PBFREE](#)