



Power Transistors

TO-220 Case (Continued)

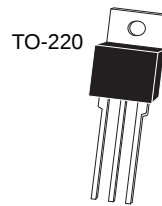

Standard

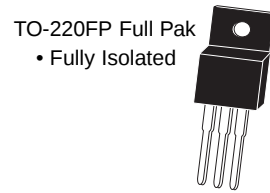

Optional

TYPE NO.		I _C	P _D	BV _{CBO}	BV _{CEO}	h _{FE}		@ I _C	V _{CE(SAT)}	@ I _C	f _T
NPN	PNP	(A) MAX	(W)	(V) MIN	(V) MIN	MIN	MAX	(A)	(V) MAX	(A)	(MHz) MIN
2N6497		5.0	80	350	250	10	75	2.5	5.0	5.0	5.0
2N6498		5.0	80	400	300	10	75	2.5	5.0	5.0	5.0
2N6499		5.0	80	450	350	10	75	2.5	5.0	5.0	5.0
2N6530		8.0	65	80	80	1,000	10,000	5.0	3.0	8.0	20
2N6531		8.0	65	100	100	500	10,000	3.0	3.0	8.0	20
2N6532		8.0	65	100	100	1,000	10,000	5.0	3.0	8.0	20
2N6533		8.0	65	120	120	1,000	10,000	3.0	3.0	8.0	20
BU406		7.0	60	400	200	--	--	--	1.0	5.0	10
BU406D		7.0	60	400	200	--	--	--	1.0	5.0	10
BU407		7.0	60	330	150	--	--	--	1.0	5.0	10
BU407D		7.0	60	330	150	--	--	--	1.0	5.0	10
BU408		7.0	60	400	200	--	--	--	1.0	6.0	10
BU408D		7.0	60	400	200	--	--	--	1.0	6.0	10
BU806		8.0	60	400	200	--	--	--	1.5	5.0	--
BU807		8.0	60	330	150	--	--	--	1.5	5.0	--
D44C11		4.0	30	80	80	20	--	2.0	0.5	1.0	50
D44H11	D45H11	10	50	80	80	40	--	1.0	1.0	8.0	40
MJE800T	MJE700T	4.0	50	60	60	750	--	1.5	2.5	1.5	1.0
MJE801T	MJE701T	4.0	50	60	60	750	--	2.0	2.8	2.0	1.0
MJE802T	MJE702T	4.0	50	80	80	750	--	1.5	2.5	1.5	1.0
MJE803T	MJE703T	4.0	50	80	80	750	--	2.0	2.8	2.0	1.0
MJE2801T	MJE2901T	10	75	60	60	25	100	3.0	--	--	--
MJE3055T	MJE2955T	10	75	70	60	20	100	4.0	1.1	4.0	2.0
MJE13004		4.0	75	600	300	8.0	40	2.0	0.5	1.0	4.0
MJE13005		4.0	75	700	400	8.0	40	2.0	0.5	1.0	4.0
MJE13006		8.0	80	600	300	5.0	30	5.0	1.0	2.0	4.0
MJE13007		8.0	80	700	400	5.0	30	5.0	1.0	2.0	4.0
MJE13007A		8.0	80	850	400	5.0	30	5.0	3.0	8.0	4.0
MJE13008		12	100	600	300	6.0	30	8.0	1.0	5.0	4.0
MJE13009		12	100	700	400	6.0	30	8.0	1.0	5.0	4.0

Shaded areas indicate Darlington.

(6-December 2004)

Central
Semiconductor Corp.
www.centrasemi.com

OUTSTANDING SUPPORT AND SUPERIOR SERVICES



PRODUCT SUPPORT

Central's operations team provides the highest level of support to insure product is delivered on-time.

- Supply management (Customer portals)
- Inventory bonding
- Consolidated shipping options
- Custom bar coding for shipments
- Custom product packing

DESIGNER SUPPORT/SERVICES

Central's applications engineering team is ready to discuss your design challenges. Just ask.

- Free quick ship samples (2nd day air)
- Online technical data and parametric search
- SPICE models
- Custom electrical curves
- Environmental regulation compliance
- Customer specific screening
- Up-screening capabilities
- Special wafer diffusions
- PbSn plating options
- Package details
- Application notes
- Application and design sample kits
- Custom product and package development

REQUESTING PRODUCT PLATING

1. If requesting Tin/Lead plated devices, add the suffix " TIN/LEAD" to the part number when ordering (example: 2N2222A TIN/LEAD).
2. If requesting Lead (Pb) Free plated devices, add the suffix " PBFREE" to the part number when ordering (example: 2N2222A PBFREE).

CONTACT US

Corporate Headquarters & Customer Support Team

Central Semiconductor Corp.
145 Adams Avenue
Hauppauge, NY 11788 USA
Main Tel: (631) 435-1110
Main Fax: (631) 435-1824
Support Team Fax: (631) 435-3388
www.centrasemi.com

Worldwide Field Representatives:
www.centrasemi.com/wwreps

Worldwide Distributors:
www.centrasemi.com/wwdistributors

For the latest version of Central Semiconductor's **LIMITATIONS AND DAMAGES DISCLAIMER**, which is part of Central's Standard Terms and Conditions of sale, visit: www.centrasemi.com/terms

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Central Semiconductor:](#)

[MJE2801T TIN/LEAD](#)