




TOP VIEW

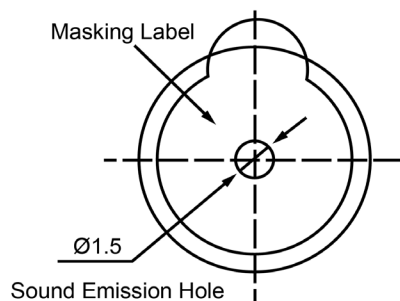

SIDE VIEW

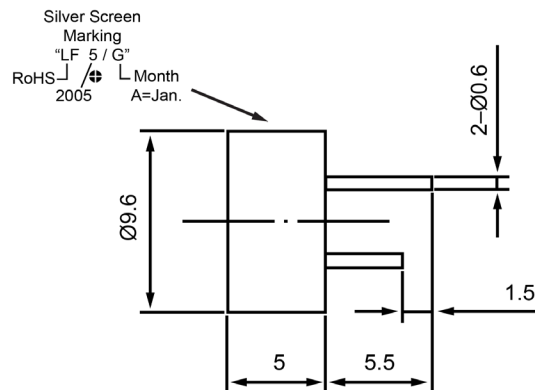

BOTTOM VIEW

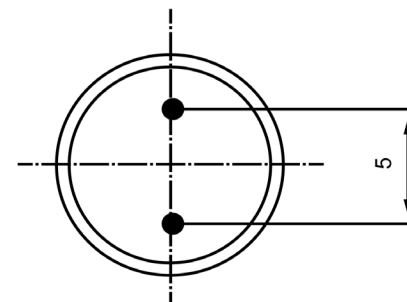

Specifications

Description	Value	Unit
Technology	Electro-Mechanical	
Resonant Frequency	2,500	(Hz)
Rated Voltage	3	(V)
SPL @ 10cm	73	(dBA)
Tone	Single	
Mount Type	Thru Hole	
Voltage Range	2 ~ 5	(V)
Max Rated Current	20	(mA)
Housing Material	NORYL	
Operating Temperature	-25 ~ +70	°C
Storage Temperature	-25 ~ +70	°C
Weight	1	(g)

Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



Revision History

Version	Description	Date	Approved		
1	Released from Engineering	10/21/2013	J.S		
Drawn by	Date	Checked by	Date	Approved by	Date
A.B.	10/21/2013	C.E.	10/21/2013	J.S	10/21/2013

Electro-Mechanical Indicator

IE092503-1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IE092503-1](#)