





DB UNLIMITED

Part Number:	IE092505-1	DRAWN CJ	5/31/2019
		CHECKED C.H.	6/4/2019
Description:	Electro-Mechanical Indicator	APPROVED C.E.	6/4/2019
		This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at <a href="http://www.dbunlimitedco.com">www.dbunlimitedco.com</a>	


Top View

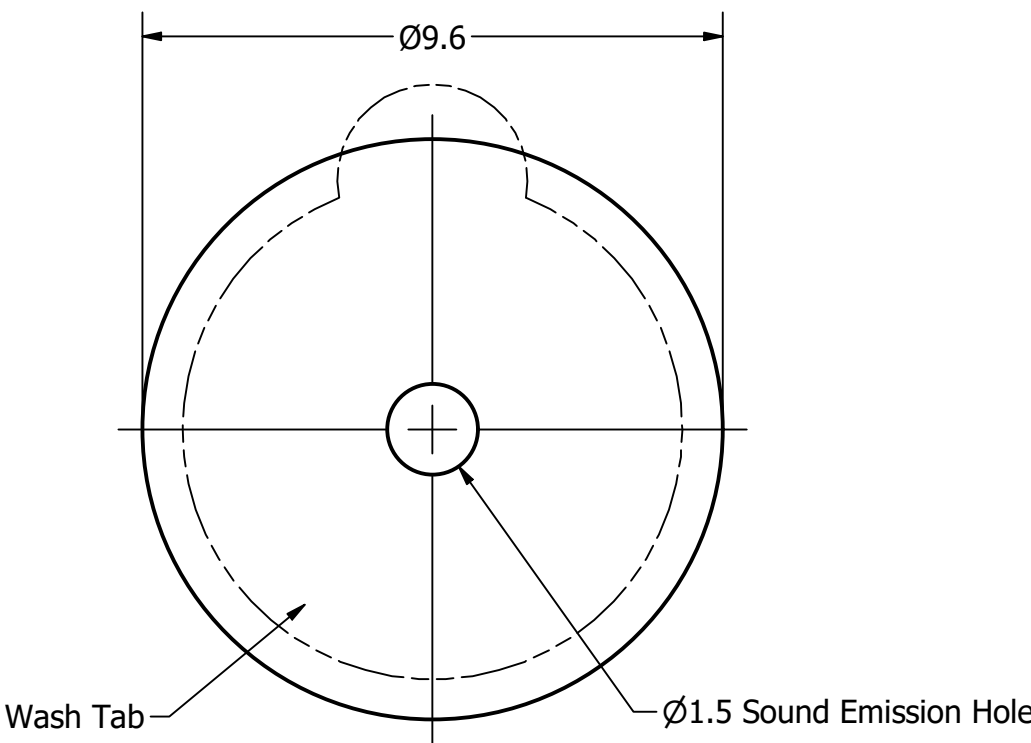

Side View

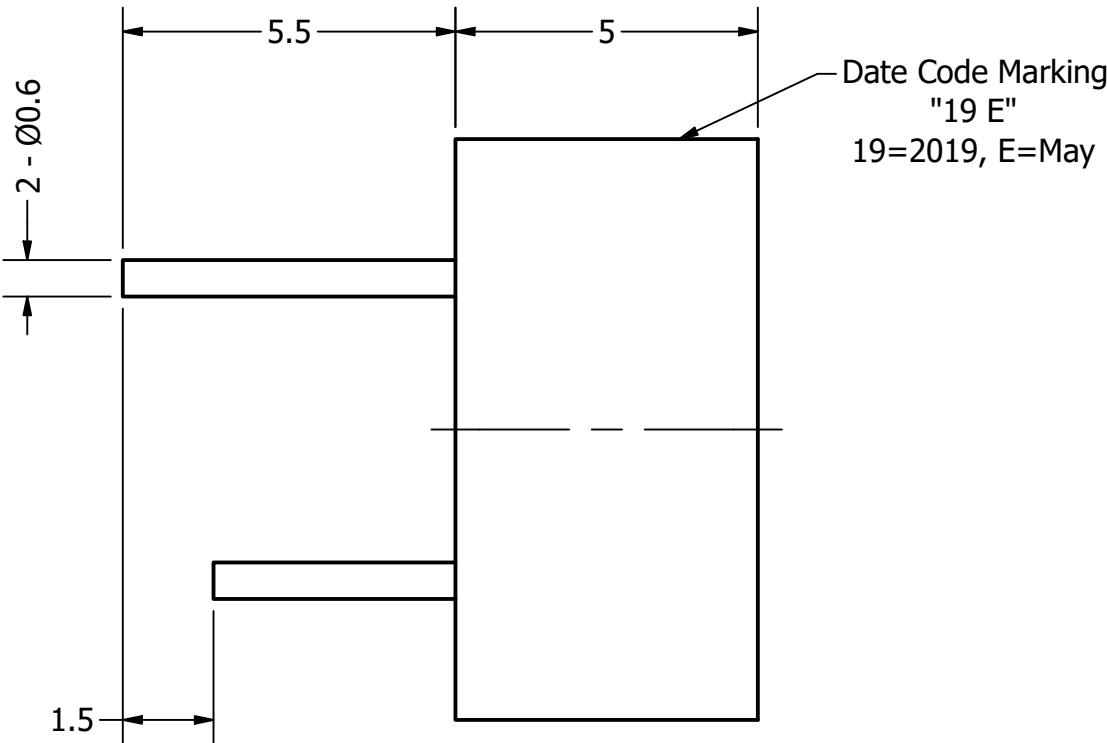

Bottom View

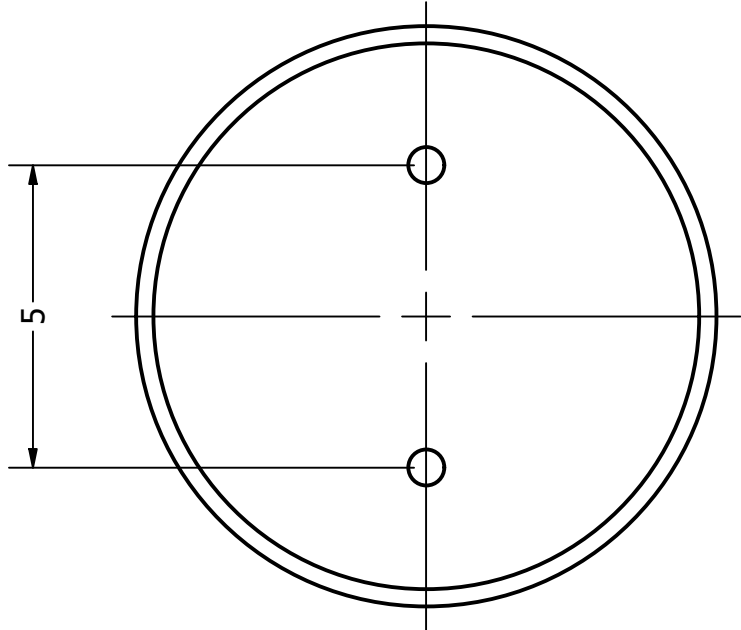

Items	Specifications	Conditions				
Min. Sound Pressure Level	80	dB (@ 10cm)				
Tone	Single					
Resonant Frequency	2,700	Hz	REVISION HISTORY			
Rated Voltage	5	V	REV	DESCRIPTION	DATE	APPROVED
Voltage Range	3 ~ 7	V		Released from Engineering	10/21/2013	J.S.
Max. Rated Current	30	mA	1	Updated drawing template, current, SPL, frequency, temps, housing material	6/4/2019	C.E.
Storage Temperature	-20 ~ +70	°C				
Operating Temperature	-20 ~ +70	°C	NOTES			
Connection Method	PC Pin		1) All dimensions are in mm unless otherwise noted			
Mount Type	Thru-Hole		2) All tolerances are ± 0.5 mm unless otherwise noted			
Housing Material	PBT		3) All parts meet RoHS			
Weight	1	g	4) Subject to change or redrawn without notice			

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IE092505-1](#)